

Mounting feet with integrated castors

Offset castor

PDR


- Combines the advantages of a static mounting foot and a castor
- Use a hexagonal spanner to release the castor
- Castor protrudes 12.5mm when released
- Only for use on surfaces that are smooth (crevices less than 5mm) and horizontal (max slope 3°)
- Max static load 2,500 kg per foot
- Max load 200 kg per foot if used in movable mode
- Materials:
 - Base - Polyamide
 - Sole - NBR rubber
 - Threaded shaft - Chromed steel

Typical application


- A vessel remains static whilst the product within is processed but once empty, can be moved for cleaning purposes.

Advantages

- Flexibility (1 item performs 2 functions)
- Less manoeuvring to move a structure
- Time saving

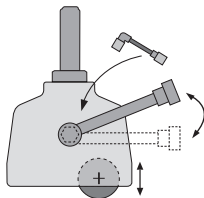

Retracting the castor

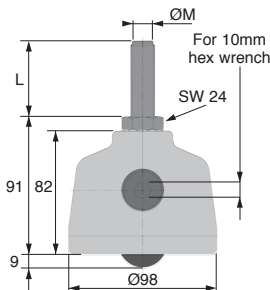

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØM	L	Load Castor fixed (static) (kg)	Load Castor free (dynamic) (kg)	Price each 1 to 5
With threaded shaft					
PDR100-16-50/RD	M16	50	2500	200	118,60 €
PDR100-16-100/RD	M16	100	2500	200	122,18 €
PDR100-20-75/RD	M20	75	2500	200	122,18 €
PDR100-20-125/RD	M20	125	2500	200	125,78 €
PDR100-24-75/RD	M24	75	2500	200	122,18 €
PDR100-24-125/RD	M24	125	2500	200	125,78 €
With 80x80mm mounting plate					
PDR100-80-80/RD	4x8.5mm holes		2500	200	122,18 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Altri prodotti...



RHTtcss
Ruota alte temperature con foro centrale, fino a 200kg



BEF
Vite a ricircolo di sfere miniatura, Supporto con cuscinetto



METC
Cuscinetto a collare, Bronzo autolubrificante



RPCpl
Ruota girevole con piastra, Acciaio - Poliammide



RJA00_28
Guarnizione in gomma, Da agganciare



MET
Cuscinetto cilindrico, Bronzo autolubrificante METAFRAM



HLUMss
Impugnatura girevole, Inox 316



CHAFR
Cerniera, A frizione



SH2
Ingranaggio elicoidale ad assi paralleli, Plastica lavorata



AT10-25ECO
Puleggia dentata di posizionamento tipo AT, Serie economica -



SBF
Sealed flange bearing unit for Food Industry, cover



EKONSL
Piedino antivibrante conico silicone, Fissaggio femmina

Prodotti correlati



RIMtce
Ruota di livellamento, Con foro centrale



RIMple
Ruota di livellamento, Con piastra