

# Recessed handle, clip-in

## PENC

## Thermoplastic

- Handle for carrying or push/pull operations, mounting by clipping into a panel

Material:



Black thermoplastic (ABS)

### Info.

- Gripping force is 750N per pair in steel and sheet metal housings

### Applications

- Ideal for use on metal enclosures or drawers

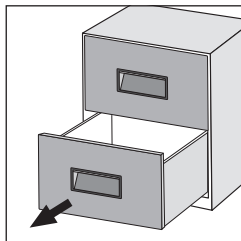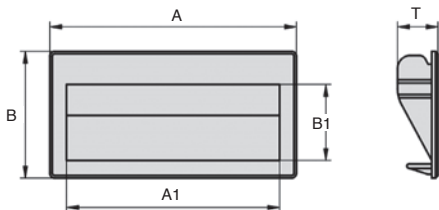

Typical application

### DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	A1	B	B1	T	Mounting hole	For wall thickness (mm)	Load (N)	Stock*	Price each 1 to 5
PENC40-90	90	79	40,0	30,0	16	83X34	0,75 à 1,5	375	✓	5,02 €
PENC56-110	110	95	56,3	33,8	18	103X49	0,75 à 1,5	375	-	5,67 €
PENC79-187	187	164	79,0	54,0	22	171X73	1,5 à 2	375	✓	7,38 €

Dimensions in mm

## Altri prodotti...




Maniglia a ponte inox,  
Inox



Vite senza fine di  
precisione, Inox




Motore AC asincrono  
trifase, 0.18 a 0.55kW

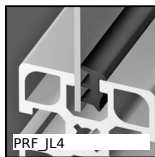

Panel accessories,  
Guarnizione - Ø 4mm



Pistoncino a molla,  
Con flangia di  
fissaggio orizzontale

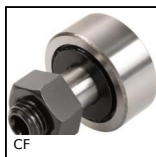

Perno folle, Standard -  
acciaio



Distanziatore  
cilindrico,  
termoplastica



Cerniera senza perno,  
Cerniera in polimero




Supporto con tirante  
ad occhio, Inox



Ruota di precisione,  
Bronzo



Catena segnaletica  
rossa e bianca,

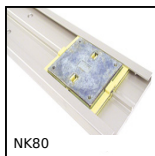

Guida mini Drylin® N,  
Larghezza 80mm

## Prodotti correlati



Maniglia da incasso,  
Ad avvitare



Maniglia a ponte -  
Multi-settore, Foro  
liscio