

Recessed handle, clip-in

PENC

Thermoplastic

- Handle for carrying or push/pull operations, mounting by clipping into a panel

Material:



Black thermoplastic (ABS)

Info.

- Gripping force is 750N per pair in steel and sheet metal housings

Applications

- Ideal for use on metal enclosures or drawers

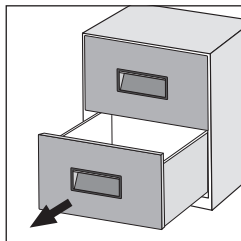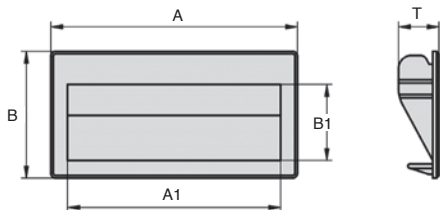

Typical application

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	A1	B	B1	T	Mounting hole	For wall thickness (mm)	Load (N)	Stock*	Price each 1 to 5
PENC40-90	90	79	40,0	30,0	16	83X34	0,75 à 1,5	375	✓	5,02 €
PENC56-110	110	95	56,3	33,8	18	103X49	0,75 à 1,5	375	-	5,67 €
PENC79-187	187	164	79,0	54,0	22	171X73	1,5 à 2	375	✓	7,38 €

Dimensions in mm

Altri prodotti...



SDG_SS

Supporto con tirante
ad occhio, Inox



CLM

Attacco per forcella,
Corta inox



RHTtcss

Ruota alte
temperature, fino a
200kg



PRES5HR

Pressa manuale da
banco, Pressione fino
a 500kg



PGB

Attrezzi, Porta attrezzi



NDS20

Connettore di
serraggio, Incrociata



GP75

Chiusura a leva molla
a trazione
compensata,
Standard (GP75)



HTD5M_09

Puleggia dentata di
trasmissione tipo
HTD, HTD5 Alluminio



CHN_CHNSS

Catena dritta a maglie
lunghe, Acciaio
zincato



CDC

Molla di compressione
conica, Conica



GEC

Chiusura a leva in
gomma con aggancio,
Bloccabile



HLA24

Rinvio angolare a
dentatura spiroidale,
Fino a 78Nm

Prodotti correlati



PENV

Maniglia da incasso,
Ad avvitare



PO

Maniglia a ponte -
Multi-settore, Foro
liscio