

# Recessed handle, screw fixing

Thermoplastic

PENV

Improved grip

- Handle for carrying or push/pull operations, mounts by clipping into a panel.

- Material:



Black thermoplastic (ABS)

## Info.


- Maximum load: 500N per pair

## Applications

- Ideal for use on metal enclosures or drawers

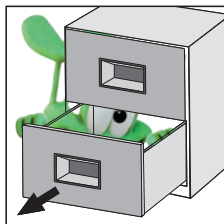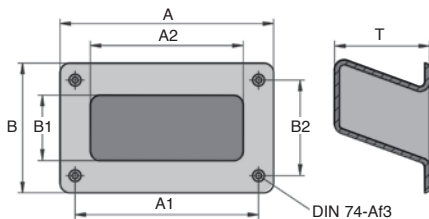

Typical application

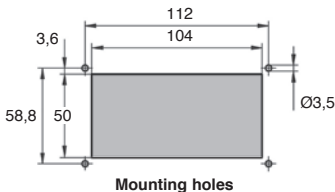

## DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	A1	A2	B	B1	B2	T	Load (N)	Stock*	Price each 1 to 5
PENV79-131	131	112	94	79,0	40,0	58,8	58	250	✓	6,56 €

Dimensions in mm

Fax 0 825 88 6000  
Service 0,15 € / min  
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

155

## Altri prodotti...



PLM-205C  
Magnete cilindrico,  
Magnete cilindrico




CHA1056-U4  
Cerniera ad avvitare,  
Aperura 180°



TRM  
Cremagliera sezione  
circolare, Acciaio -  
modulo 1-6



Gal-cardan  
Giunto cardanico  
semplice serie eco,  
Sollecitazioni leggere

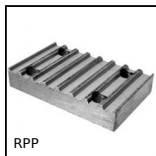

RPP  
Piastra di giunzione  
per cinghia RPP,  
RPP14




PSG35  
Ingranaggio dritto di  
precisione, Inox 316



RT25  
Calettatore di  
bloccaggio, Coppia  
media/elevata



DIA  
Pistoncino a molla,  
con anello

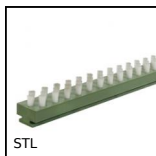


STL  
Guida con spazzola,  
Spazzola



PS5  
Riduttore a ruota e  
vite senza fine, fino a  
57 Nm



NPR  
Morsetto porta  
catarifrangente,

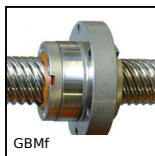

GBMf  
Dado per vite a sfere,  
Dado flangiato a  
circuiti multipli

## Prodotti correlati



PENC  
Maniglia da incasso,  
montaggio a scatto



PO  
Maniglia a ponte -  
Multi-settore, Foro  
liscio