

Recessed handle, screw fixing

Thermoplastic

PENV

Improved grip

- Handle for carrying or push/pull operations, mounts by clipping into a panel.

- Material:



Black thermoplastic (ABS)

Info.


- Maximum load: 500N per pair

Applications

- Ideal for use on metal enclosures or drawers

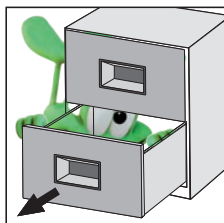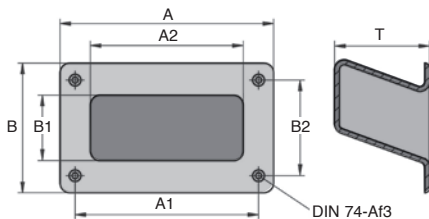

Typical application

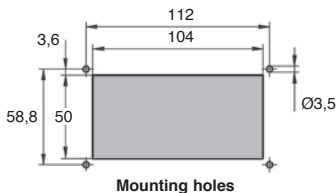

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	A1	A2	B	B1	B2	T	Load (N)	Stock*	Price each 1 to 5
PENV79-131	131	112	94	79,0	40,0	58,8	58	250	✓	6,56 €

Dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC SUPPLEMENT 2019

155

Altri prodotti...



CHTRP

Riduttore a rinvio angolare a L o a T, fino a 75,7 Nm



T5-BAR

Barra dentata, T5



PRF JL2

Panel accessories, Guarnizione - Ø 2mm



CHC

Vite a testa cava esagonale CHC, Acciaio classe 12.19



ACLERP

Rulliera, Senza guida laterale



FR

Inseri filettati, Acciaio



SMLS

Tavola lineare, Per lunghezze ridotte



CHTRB

Riduttore a rinvio angolare a L o a T, fino a 4,7 Nm



PLM-SC

Magnete piatto, With threaded hole



PR40

Piede fissabile con snodo - poliammide, Ø



ES

Simple support base (bipod), Plastic



DB

Ingranaggio conico in acciaio, 2:1

Prodotti correlati



PENC

Maniglia da incasso, montaggio a scatto



PO

Maniglia a ponte - Multi-settore, Foro liscio