

Front fixing handle



PGMT


 
Steel or stainless steel

Economy range

- Push/pull handle
- Front fixing
- Materials:
Galvanised steel
Stainless steel, 304

Info.

- The handle is made from pre-galvanized steel.
- Cut edges and holes may therefore not be galvanised

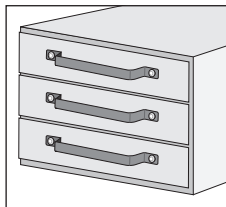

Typical application

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	Material	Finish	A	B	C	F	Weight (g)	Stock*	Price each 1 to 5
PGMT107-4/AG	Galvanised steel	Natural	107	21	15	120	32	✓	3.68 €
PGMT107-4/SS	Stainless steel 304	Deburred	107	21	15	120	32	✓	6.43 €

Dimensions in mm

Altri prodotti...



UTKpwc

Guida lineare Utilitrack®, Ruota a V - rivestimento polimero



BCM_TP

Spazzola cilindrica modulare, Filo in tampico



DB_ECO

Ingranaggio conico - Acciaio C43, 2:1



PPS15

Albero con pignone di precisione, Inox



GP75

Chiusura a leva molla a trazione compensata, Standard (GP75)



TB8

Cuscinetto assiale a rulli cilindrici, Acciaio



SSB

Ingranaggio conico inox, 1:1



BAG

Anello di bloccaggio, Acciaio



CLG15-ALI

Ingranaggio dritto, Nylon stampato



GE_ES

Snodo sferico, acciaio/acciaio



ARL_SRS

Creomaglieria flessibile plastica, Clips di fissaggio



LRR-53

Interblocco di sicurezza, Lucchetto a molla acciaio

Prodotti correlati



PGMT

Maniglia di trasporto, Inox



PO

Impugnatura di carterizzazione - Multi-settore, Foro liscio



PO

Impugnatura di carterizzazione - Multi-settore, Foro cieco maschiato



PGM52-M4

Maniglia di trasporto, Alluminio