

Front fixing handle



PGMT


 
Steel or stainless steel

Economy range

- Push/pull handle
- Front fixing
- Materials:
Galvanised steel
Stainless steel, 304

Info.

- The handle is made from pre-galvanized steel.
- Cut edges and holes may therefore not be galvanised

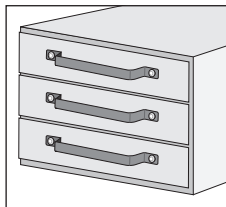

Typical application


DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	Material	Finish	A	B	C	F	Weight (g)	Stock*	Price each 1 to 5
PGMT107-4/AG	Galvanised steel	Natural	107	21	15	120	32	✓	3.68 €
PGMT107-4/SS	Stainless steel 304	Deburred	107	21	15	120	32	✓	6.43 €

Dimensions in mm

Altri prodotti...

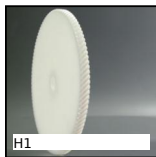

H1
Ingranaggio elicoidale ad assi incrociati a 90°, Plastica lavorata



CFES
Perno folle eccentrico, Eccentrico



PSPT
Manopola a pressione, PVC



MEB
Ingranaggio conico in plastica stampata, 1:1



CHTRP
Riduttore a rinvio angolare a L o a T, fino a 9,1 Nm



CM_CO
Attrezzi Hygienic Usit® and Hygienic Design®, Protective inserts f...



STRIP
Spazzola strip, Lunghezza 3m



P60
Riduttore a ruota e vite senza fine, fino a 118 Nm




Q4
Cuscinetto a doppia corona di sfere, Radiale - Acciaio



PRF-SCL
Sistema di chiusura per profili alluminio, Lock for sliding doors



NAST
Rotelle, Con anello interno

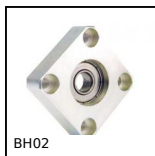

BH02
Cuscinetto radiale flangiato, Montaggio con circlips

Prodotti correlati



PGMT
Maniglia a ponte a fissaggio anteriore, Inox



PO
Maniglia a ponte - Multi-settore, Foro cieco maschiato



PO
Maniglia a ponte - Multi-settore, Foro liscio



PGM52-M4
Maniglia a ponte, Alluminio