

Thermoplastic T handle

New

PGNT

Pull or push

- Handle with threaded insert or threaded stem

- Material:

Black glass fibre reinforced thermoplastic


Threaded insert: brass

Threaded stem: Chromed steel


Advantage

- Excellent grip



- Mechanical linkage applications

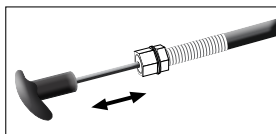

Typical application

 

T handle with insert

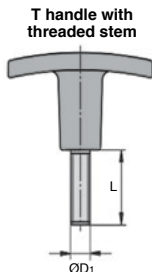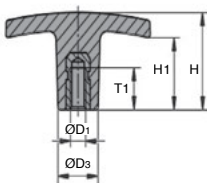

T handle with threaded stem

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	B	ØD1	ØD3	H	H1	T1	L	Weight (kg)	Price each 1 to 9
With threaded insert										
PGNT40-M5	40	13	M5	13	30,5	20	10	-	0,011	2,31 €
PGNT50-M5	50	15	M5	14	24	16	10	-	0,013	2,40 €
PGNT60-M6	60	17	M6	16	31,5	23	12	-	0,017	3,19 €
PGNT71-M8	71	19,5	M8	20	36	19	20	-	0,028	4,94 €
PGNT71-M10	71	19,5	M10	20	36	19	20	-	0,030	5,44 €
PGNT80-M10	80	26	M10	26	39,5	26	25	-	0,048	6,32 €
PGNT80-M12	80	26	M12	26	39,5	26	25	-	0,056	7,37 €
With threaded stem										
PGNT40-M5-15	40	13	M5	13	30,5	20	-	15	-	1,25 €
PGNT50-M5-20	50	15	M5	14	24	16	-	20	-	2,17 €
PGNT50-M6-25	60	17	M6	16	31,5	23	-	25	-	2,47 €
PGNT71-M8-30	71	19,5	M8	20	36	19	-	30	-	3,66 €
PGNT71-M10-30	71	19,5	M10	20	36	19	-	30	-	4,18 €
PGNT80-M10-30	80	26	M10	26	39,5	26	-	30	-	4,84 €
PGNT80-M12-40	80	26	M12	26	39,5	26	-	40	-	5,73 €

Dimensions in mm

Altri prodotti...



Q6

Cuscinetto radiale a sfere, Acciaio



NJM

Connettore rinvio d'angolo, Multiplo



BAN

Connettore / supporto per profili alluminio, Universale



LVT

Mini martinetto motorizzato 2A, 2 ampere



PLB

Distanziatore cilindrico, Ottone



HLU

Volantino con razze, Alluminio



AT5-BAR

Barra dentata, AT5



SRP

Spina cilindrica ISO8752, elastica ISO 8752



T39_T49

Molla di trazione al metro inox, al metro



MAX22

Motoriduttore DC 12V e 24V DC, da 0,07 a 0,2Nm



HTD5M_09

Puleggia dentata di trasmissione tipo HTD, HTD5 Alluminio



PR105

Piede fissabile con snodo - poliammide, Ø 103

Prodotti correlati



PGNT

Impugnatura termoplastica a T, Con inserto maschiato



PCH

Impugnatura, Fungo