

Thermoplastic T handle

New

PGNT

Pull or push

- Handle with threaded insert or threaded stem

- Material:

Black glass fibre reinforced thermoplastic


Threaded insert: brass

Threaded stem: Chromed steel


Advantage

- Excellent grip



- Mechanical linkage applications

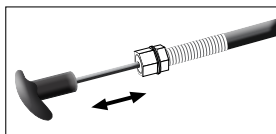

Typical application

 

T handle with insert

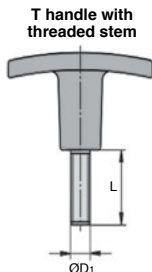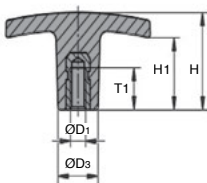

T handle with threaded stem

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	B	ØD1	ØD3	H	H1	T1	L	Weight (kg)	Price each 1 to 9
With threaded insert										
PGNT40-M5	40	13	M5	13	30,5	20	10	-	0,011	2,31 €
PGNT50-M5	50	15	M5	14	24	16	10	-	0,013	2,40 €
PGNT60-M6	60	17	M6	16	31,5	23	12	-	0,017	3,19 €
PGNT71-M8	71	19,5	M8	20	36	19	20	-	0,028	4,94 €
PGNT71-M10	71	19,5	M10	20	36	19	20	-	0,030	5,44 €
PGNT80-M10	80	26	M10	26	39,5	26	25	-	0,048	6,32 €
PGNT80-M12	80	26	M12	26	39,5	26	25	-	0,056	7,37 €
With threaded stem										
PGNT40-M5-15	40	13	M5	13	30,5	20	-	15	-	1,25 €
PGNT50-M5-20	50	15	M5	14	24	16	-	20	-	2,17 €
PGNT50-M6-25	60	17	M6	16	31,5	23	-	25	-	2,47 €
PGNT71-M8-30	71	19,5	M8	20	36	19	-	30	-	3,66 €
PGNT71-M10-30	71	19,5	M10	20	36	19	-	30	-	4,18 €
PGNT80-M10-30	80	26	M10	26	39,5	26	-	30	-	4,84 €
PGNT80-M12-40	80	26	M12	26	39,5	26	-	40	-	5,73 €

Dimensions in mm

Altri prodotti...



CQA20
Accessori per slitta di regolazione miniatura, 20



YG2
Ingranaggio dritto PRESTAZIONE, Acciaio 35NCD6



LVT
Mini martinetto motorizzato 1A, 1 ampere



DOMI120
Accessori di collegamento, Piastra



NPR
Morsetto porta catarifrangente,



HTD8M_20
Puleggia dentata di trasmissione tipo HTD, HTD8 Ghisa




YG0
Ingranaggio dritto PRESTAZIONE, Acciaio 35NCD6



KB_WW
Manicotto chiuso a sfere di precisione, Economica



MAX22
Motoriduttore DC 12V e 24V DC, da 0,07 a

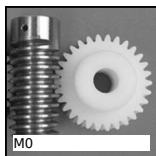

M0
Coppia ruota e vite senza fine, Plastica



RBS
Rondella elastica, Acciaio



PW_PWG2
Ruota di precisione, Bronzo

Prodotti correlati



PGNT
Impugnatura termoplastica a T, Con inserto maschiato



PCH
Impugnatura, Fungo