


- For square tube $\square 25 \times 25$
- Material: polyethylene
- Colour: black

Accessories


- Structural tube **TUBE**
- Support profiles **PSP**

Info.

- **PGT25-D** comprises 2 elements, top and bottom

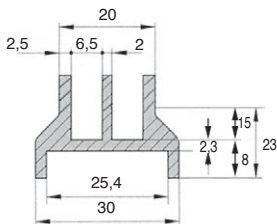


Top part

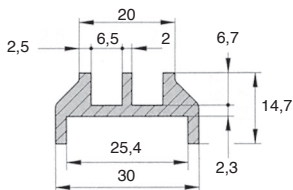

Profile type PGT-D

Bottom part

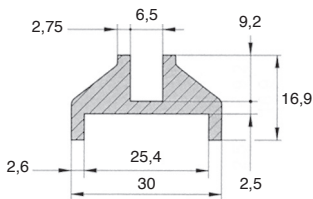

Profile type PGT-S



Typical application

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List -5%	On request	

Part number	Type	Length (mm)	Weight (kg/m)	Stock*	Price each 1 to 4
PGT25-S	Single	2000	0,53	✓	28,01 €
PGT25-D	Double	2000	0,85	✓	221,69 €

*Depending on availability - Dimensions in mm

Altri prodotti...



BDPR

Braccio di reazione,
Rigido



GSI_A

Vite di regolazione per
molla a gas, Vite di
regolazione



TBD

Tavola di
posizionamento a
passo inverso
manuale, 20kg




DOMI30

Slitta di regolazione
Domino 30, Slitta
DOMILINE 30 con
contatore e ...



PRF_CH

Catena porta cavo,
Supplied in metre
lengths

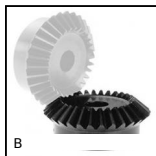

B

Ingranaggio conico -
Acciaio 60C40, 1:1



PRS100

Piede snodabile tutto
inox Ø100, Ø 100



CHA35

Cerniera ad avvitare,
Hinge



PO

Maniglia a ponte -
Multi-settore, Foro
cieco maschiato




SVG

Chiusura a leva
regolabile, Corsa da
82mm a 92mm



CHML63

Riduttore a ruota e
vite senza fine, fino a
138 Nm - Con

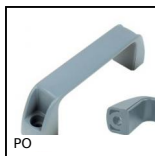

PO

Maniglia a ponte -
Multi-settore, Foro
liscio

Prodotti correlati



TUBE25_25

Tubo quadrato,
Alluminio



NCT

Giunto di
collegamento, Ad
angolo fisso



NCT

Giunto di
collegamento, Ad
angolo fisso



NCT

Giunto di
collegamento, Ad
angolo fisso