





- For square tube  $\square 25 \times 25$
- Material: polyethylene
- Colour: black

### Accessories

- Structural tube **TUBE**
- Support profiles **PSP**

### Info.

- **PGT25-D** comprises 2 elements, top and bottom

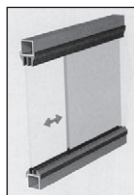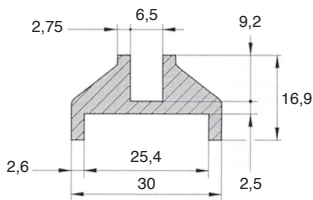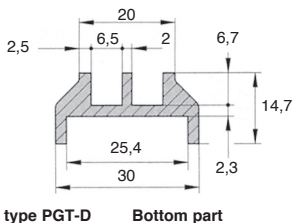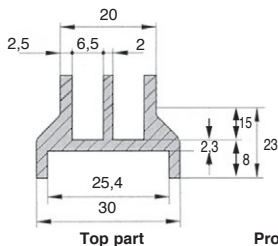

Typical application

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List -5%	On request	

Part number	Type	Length (mm)	Weight (kg/m)	Stock*	Price each 1 to 4
PGT25-S	Single	2000	0,53	✓	28,01 €
PGT25-D	Double	2000	0,85	✓	221,69 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...



PTA80  
Piede snodato con  
base stampata Ø80,  
10000N



GMK17\_BR  
Morsetto porta guide,  
Conico doppio



CHN\_CHNSS  
Catena dritta a maglie  
lunghe, Inox



EMR  
Volantino zigrinato a  
serraggio rapido,  
Zigrinato




gt64  
Chiusura a farfalla,  
Tolleranze di  
montaggio normali



M  
Manicotto per giunto  
cardanico, Accessori




DOG316  
Motoriduttore DC 12V  
e 24V DC, da 1.5 a 2  
Nm

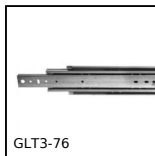

GLT3-76  
Guide telescopiche  
acciaio, Estensione  
totale



CLQ  
Cuscinetti a sfere -  
Accessorio, Spessori

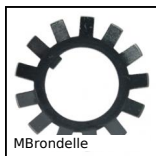

MBrondele  
Cuscinetti a sfere -  
Accessorio, Rondella



PW\_PWG15  
Vite senza fine di  
precisione, Inox



PW\_PWG1  
Ruota di precisione,  
Bronzo

## Prodotti correlati



TUBE25\_25  
Tubo quadrato,  
Alluminio



NCT  
Giunto di  
collegamento, Ad  
angolo fisso



NCT  
Giunto di  
collegamento, Ad  
angolo fisso



NCT  
Giunto di  
collegamento, Ad  
angolo fisso