




- For square tube $\square 25 \times 25$
- Material: polyethylene
- Colour: black

Accessories

- Structural tube **TUBE**
- Support profiles **PSP**

Info.

- **PGT25-D** comprises 2 elements, top and bottom

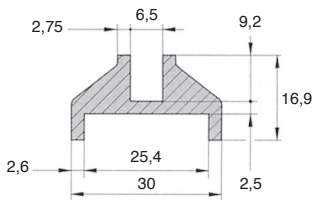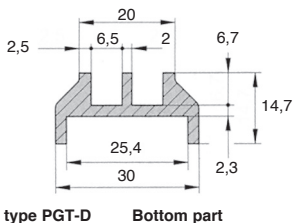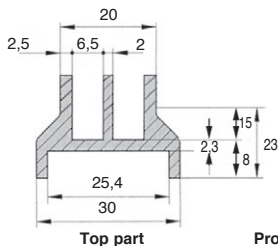

Typical application

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List -5%	On request	

Part number	Type	Length (mm)	Weight (kg/m)	Stock*	Price each 1 to 4
PGT25-S	Single	2000	0,53	✓	28,01 €
PGT25-D	Double	2000	0,85	✓	221,69 €

*Depending on availability - Dimensions in mm

Altri prodotti...



GLT3E-58

Guide telescopiche
acciaio, Estensione
extra



DOMI80

Slitta di regolazione
Domino 80, Slitta
DOMILINE 80



PTR

Pignone tendicatena,
Per applicazioni
correnti



GE14

Chiusura a leva, Con
porta-lucchetto



NCT

Giunto di
collegamento, Ad
angolo fisso



PR85

Piede fissabile con
snodo - poliammide, Ø
83



RBNpl

Ruota girevole a
doppio bloccaggio,
Acciaio - caucciù



EMS

Volantino zigrinato,
Zigrinato



DIA

Pistoncino a molla,
con anello



PR125

Piede fissabile con
snodo - poliammide, Ø
123



CHMR63

Riduttore a ruota e
vite senza fine, fino a
196 Nm



DOMI80

Slitta di regolazione
Domino 80, Slitta
DOMILINE 80 con
contatore e ...

Prodotti correlati



TUBE25_25

Tubo quadrato,
Alluminio



NCT

Giunto di
collegamento, Ad
angolo fisso



NCT

Giunto di
collegamento, Ad
angolo fisso



NCT

Giunto di
collegamento, Ad
angolo fisso