

Multi-sector enclosure/door handle

PO

Back to back mounting

- Ideal for back mounting, i.e. a PO handle used on one side with a PO-M handle on the other (see typical application)

- Colour: matt black

- Materials:

Handle: Fibreglass reinforced Technopolymer

Insert: Brass (PO-M version)

- PO version has a smooth bored hole for socket head screw

- PO-M has a blind threaded insert



PO version



PO-M version



Black



Red: safety

Add: /R
to end of part N°



Orange:

furniture, kitchens

Add: /O
to end of part N°




 


Grey: food industry

Add: /G
to end of part N°



White: medical

Add: /B
to end of part N°

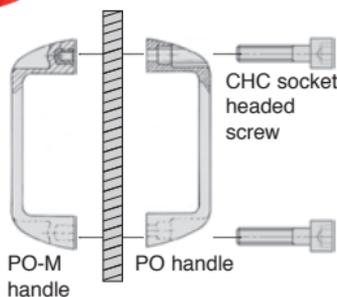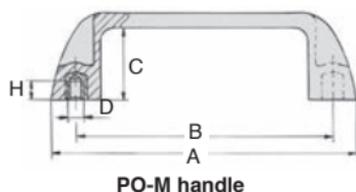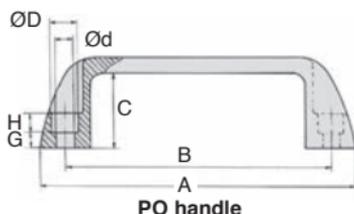

Back to back mounting

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	B	A	E	F	C	G	H	ØD	Ød	Stock*	Price each 1 to 5
With smooth hole											
PO93-6	93,5	112	21	36	30	6	7	10,5	6,5	✓	3,68 €
PO117-6	117	139	26	41	34	6	9	10,5	6,5	✓	4,00 €
PO117-8	117	139	26	41	34	6	9	13,0	8,5	✓	4,00 €
PO132-6	132	156	27	45	37	9	7	10,5	6,5	✓	5,46 €
PO132-8	132	156	27	45	37	7	9	13,0	8,5	✓	8,02 €
PO179-8	179	204	28	50	42	8	9	13,0	8,5	✓	8,02 €
With threaded hole											
PO93-M5	93,5	112	21	36	30	-	9	M5	-		5,35 €
PO93-M6	93,5	112	21	36	30	-	9	M6	-	✓	5,63 €
PO117-M6	117	139	26	41	34	-	9	M6	-	✓	5,92 €
PO117-M8	117	139	26	41	34	-	9	M8	-	✓	5,92 €
PO132-M6	132	156	27	45	37	-	9	M6	-	✓	6,61 €
PO132-M8	132	156	27	45	37	-	9	M8	-	✓	6,61 €
PO179-M8	179	204	28	50	42	-	9	M8	-	✓	9,56 €

*Depending on availability - Dimensions in mm

Altri prodotti...



PTMR
Telescopic furniture
foot, threaded stud



FBL6000_K1
Spazzola al metro
fibre PA6 da Ø0,2 a
Ø0,3, Poliammide
nero 6 - pi...




METC
Cuscinetto a collare,
Bronzo
autolubrificante
METAFRAM



R206
Molla per stampi
ISO10243, Extra-forte



MCL
Manicotto di
riduzione, Cilindrico -
acciaio

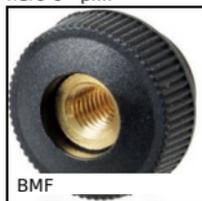

BMF
Manopola, Zigrinata -
Passante



PRES
Accessori per pressa
PRES-3HR e
PRES-4HR, Portapinz



SVT15
Martinetto a vite - Vite
traslante, Vite
traslante



VTA
Limitatore di coppia
ad attrito Vari-Tork®,



PRF_RR
Elementi di giunzione,
Piastra di raccordo



BLH60
Rinvio angolare a L,
da 19 a 70 Nm



PW_PWG2
Vite senza fine di
precisione, Acciaio

Prodotti correlati



CHCSS
Vite a testa cava
esagonale CHC, Inox -
A2



PO
Maniglia a ponte -
Multi-settore, Foro
cieco maschiato



PGMSS
Maniglia a ponte inox,
Inox



PCatherm
Pull handle,
Thermoplastic