

Indexing plunger

PPG
PPH

With horizontal mounting flange

- Mounting flange with screw holes

- Materials:

Body: Die cast zinc with black plastic coating




Pin: Stainless steel i.4305

Button : PA6 with black matt finish


- Working temp range: -30 /+80 °C

Info

- For the version that locks in the open position, the button is pulled, turned through 90°, it will be retained by a notch.

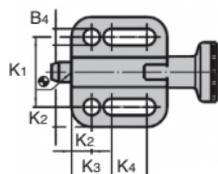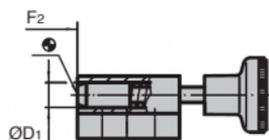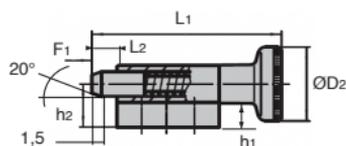

Locking version

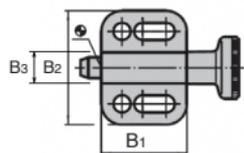

Version without locking



DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	

Part number	Locking	ØD1	ØD2	B1	B2	B3	B4 (-0,2)	h1	h2
PPG4-16-22	Without	4	12	16,5	22	6	3,3	4	7
PPG5-22-28	Without	5	16	22	28	8	4,3	4,5	9,5
PPG6-27-32	Without	6	18	27,5	32	10	5,4	5	10,5
PPG8-33-34	Without	8	21	33	34	12	5,4	6	12,5
PPH4-19-22	With	4	12	19	22	6	3,3	4	7
PPH5-25-28	With	5	16	25,5	28	8	4,3	4,5	9,5
PPH6-30-32	With	6	18	30,5	32	10	5,4	5	10,5
PPH8-37-34	With	8	21	37,5	34	12	5,4	6	12,5

Part number	K1 (+/-0,05)	K2	K3	K4	L1	L2	Pressure F1 (N)	Pressure F2 (N)	Weight (g)	Price each 1 to 5
PPG4-16-22	14	4	8	4,5	30,5	4	3	12	11	10,09 €
PPG5-22-28	18	5	10	7	40	5	5	24	20	10,84 €
PPG6-27-32	21	5,5	12	10	49	6	5	21	37	12,44 €
PPG8-33-34	23	5,5	12	15,5	59	8	6	22	61	14,00 €
PPH4-19-22	14	4	8	4,5	33	4	3	12	10	10,18 €
PPH5-25-28	18	5	10	10,5	43,5	5	5	24	26	10,84 €
PPH6-30-32	21	5,5	12	13	52	6	5	21	40	12,44 €
PPH8-37-34	23	5,5	12	20	63,5	8	6	22	67	14,11 €

*Depending on availability - Dimensions in mm

Indexing plunger with pull ring

With horizontal mounting flange



PPJ

- **Mounting flange with screw holes**
- **Materials:**
 - Body: Die cast zinc with black plastic coating
 - Pin: Stainless steel 1.4305
 - Pull ring: Stainless steel 1.4305
- **Working temp range:** -30 /+100 °C

Info

- Thanks to the pull ring, it is possible to automate the action of the index plunger with using a pneumatic actuator or some other remote control system.

Pull the ring to unlock

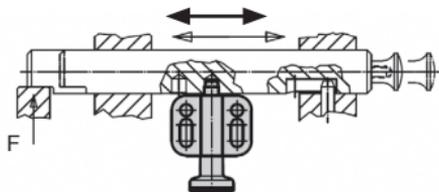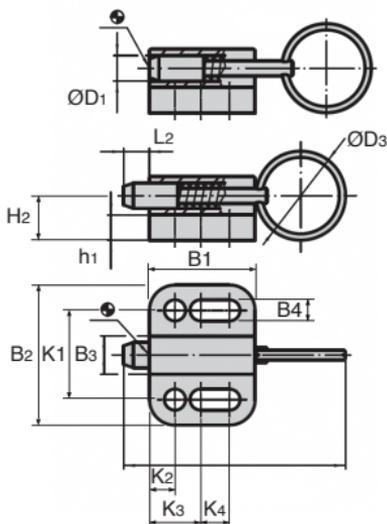

Typical application

IN STOCK*
Otherwise contact us

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	

Part number	Locking	ØD1	ØD3	B1	B2	B3	B4 (-0,2)	h1	h2
PPJ4-16-22	Without	4	14	16,5	22	6	3,3	4	7
PPJ5-22-28	Without	5	18	22	28	8	4,3	4,5	9,5
PPJ6-27-32	Without	6	24	27,5	32	10	5,4	5	10,5
PPJ8-33-34	Without	8	30	33	34	12	5,4	6	12,5

Part number	K1 (+/-0,05)	K2	K3	K4	L1	L2	Pressure F1 (N)	Pressure F2 (N)	Weight (g)	Price each 1 to 5
PPJ4-16-22	14	4	8	4,5	34,5	4	3	12	10	9,62 €
PPJ5-22-28	18	5	10	7	45	5	5	24	20	9,99 €
PPJ6-27-32	21	5,5	12	10	57,5	6	5	21	40	11,26 €
PPJ8-33-34	23	5,5	12	15,5	71	8	6	22	58	12,14 €

*Depending on availability - Dimensions in mm