



Idler sprocket for plate chain

For chain ranges 821 and 805



PR821

- For use with CAP821 and CAP805 plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

Easy assembly

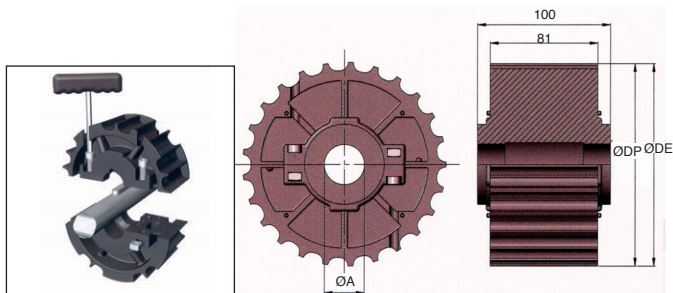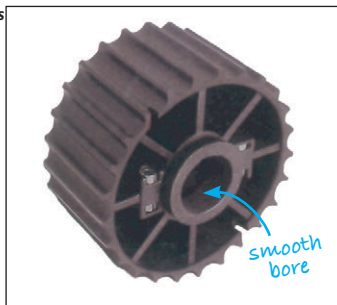

Two part design

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR821-25-30	25	153	153,2	30	0,9	70,12 €
PR821-25-35	25	153	153,2	35	0,9	70,12 €
PR821-25-40	25	153	153,2	40	0,9	70,12 €
PR821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

Altri prodotti...



ADL

Anello di sollevamento, Femmina



PRES3HR

Pressa manuale da banco, Pressione fino a 400kg



RHT

Ruota alte temperature, fino a 200kg



RAGFLOW

Rotaia a rulli Floway2®, Rotaia a rulli



SCH

Attrezzo di bloccaggio, A tirante orizzontale - inox



PRF_CLIP_45

Clip di fissaggio per cavi per profili alluminio, Per canalina di ca...



DOMI50

Slitta di regolazione Domino 50, Slitta DOMILINE 50



CHA_GC_955

Cerniera a bandiera inox, A saldare



CHM110

Riduttore a ruota e vite senza fine, fino a



NSA

Connettore rinvio d'angolo, Articolato



LRR

Chiavistello con perno prismatico, Lucchetto



CLSCLP

Forcella serie corta, Corta acciaio

Prodotti correlati