



Idler sprocket for plate chain

For chain ranges 821 and 805



PR821

- For use with CAP821 and CAP805 plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

Easy assembly

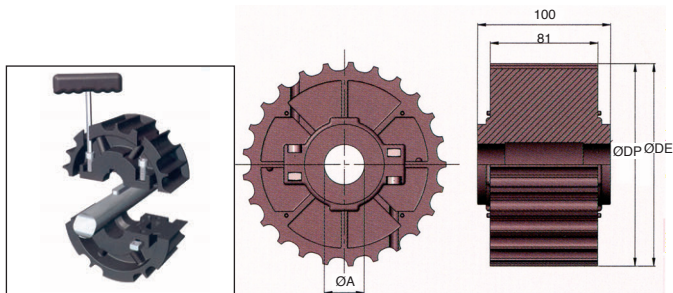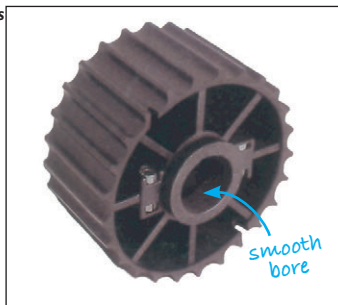

Two part design

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty. | 1+ | 5+ | 10+ |
| Disc. | List | -5% | On request |

| Part number | No. of teeth | ØDE | ØDP | Bore ØA | Weight (kg) | Price each 1 to 4 |
|-------------|--------------|-----|-------|---------|-------------|-------------------|
| PR821-25-30 | 25 | 153 | 153,2 | 30 | 0,9 | 70,12 € |
| PR821-25-35 | 25 | 153 | 153,2 | 35 | 0,9 | 70,12 € |
| PR821-25-40 | 25 | 153 | 153,2 | 40 | 0,9 | 70,12 € |
| PR821-25-45 | 25 | 153 | 153,2 | 45 | 0,9 | 70,12 € |

Dimensions in mm

Altri prodotti...



MDB_MTB
Ingranaggio conico in
plastica stampata ,
3:1



PR882
Ruota di rinvio, Serie
882



CHA60
Cerniera,
 Rettangolare forata o
con fori svasati



HTD5M_25
Puleggia dentata di
trasmissione tipo
HTD, HTD5 Alluminio



CHAR7530
Cerniera a molla,
saldabile



PVL
Volantino a lobi,
Poliammide



DB
Ingranaggio conico in
acciaio, 2:1



PDD
Pressore a molla
sensore di
rilevamento, Con asta
di comando per int...



H2
Ingranaggio elicoidale
ad assi incrociati a
90°, Acciaio 20NCD2



PRF_FIX_ANG
Fissaggio, Fissaggio
angolare



PGM52-M4
Maniglia a ponte,
Ottone



RBGpl
Ruota fissa con
piastra, Acciaio -
gomma grigia

Prodotti correlati