



Idler sprocket for plate chain

For chain ranges 821 and 805


PR821

- For use with CAP821 and CAP805 plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

Easy assembly

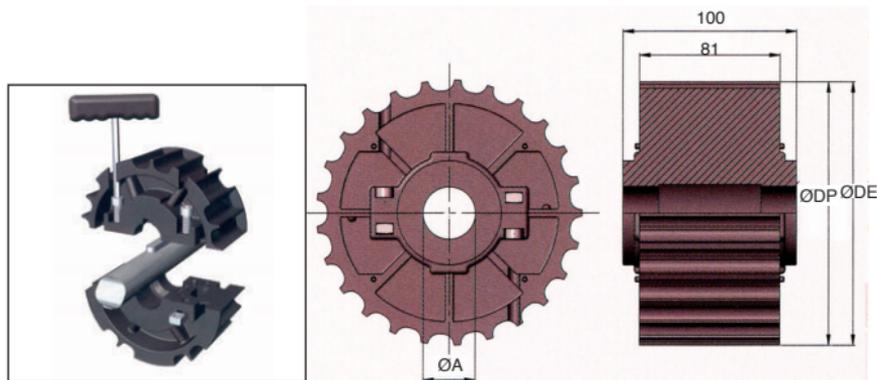

Two part design

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR821-25-30	25	153	153,2	30	0,9	70,12 €
PR821-25-35	25	153	153,2	35	0,9	70,12 €
PR821-25-40	25	153	153,2	40	0,9	70,12 €
PR821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

Altri prodotti...



COA-COG

Staffa di montaggio per molla a gas, Staffa di montaggio piana per f...



GP

Chiusura a leva molla a trazione compensata, Standard



SVT30

Martinetto a vite - Vite traslante, Vite traslante



CHTRB

Riduttore a rinvio angolare a L o a T, fino a 87,3 Nm



AT5P_AT10P

Piastra di giunzione per cinghia AT, AT5



VELM4

Supporto avvitabile per rotolo a strappo fermacavi, Poliammide



TCLar

Tenditore per catena automatico, Con pattino largo



AT10courroie

Cinghia di posizionamento AT, AT10 Poliuretano armatura in acciaio



PSG08S

Ingranaggio dritto di precisione, Inox 316




Gdal

Giunto cardanico doppio serie eco, Sollecitazioni leggere



TAC

Tenditore, Acciaio

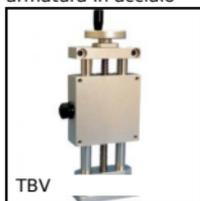

TBV

Tavola di posizionamento verticale manuale, 7kg

Prodotti correlati