



# Idler sprocket for plate chain

For chain ranges 821 and 805



PR821

- For use with CAP821 and CAP805 plate chains
- Materials:  
Reinforced polyamide  
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,  
please refer to technical pages

## Advantage

- Two part design facilitates easy assembly

Easy assembly

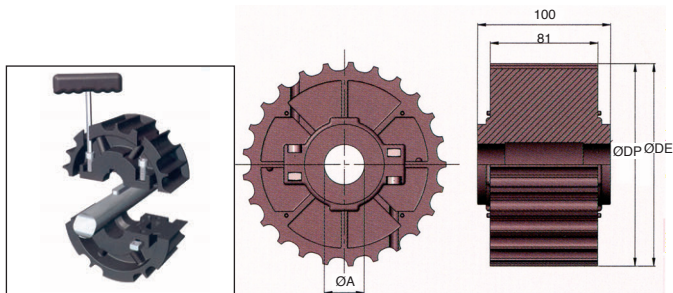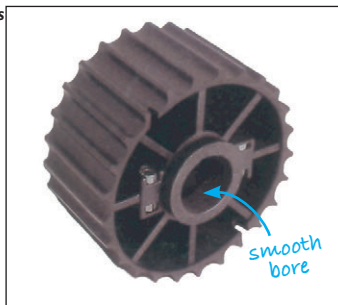

Two part design

## DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR821-25-30	25	153	153,2	30	0,9	70,12 €
PR821-25-35	25	153	153,2	35	0,9	70,12 €
PR821-25-40	25	153	153,2	40	0,9	70,12 €
PR821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

## Altri prodotti...



G-ECO

Ingranaggio dritto acciaio - serie ECO, Acciaio C45



PSG08S

Ingranaggio dritto di precisione, Inox 316



CNA-CNG

Staffa di montaggio per molla a gas, Staffa di montaggio a squadra p...



BLH20

Rinvio angolare a L, da 0.53 a 1.77




CQA30

Slitta di regolazione miniatura, 30



ADL\_M

Anello di sollevamento, Inox

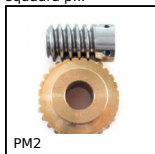

PM2

Coppia ruota e vite senza fine, Bronzo



VQTplq

Chiusura ¼ di giro - Piastra di bloccaggio, Montaggio con controd...



CHAR

Cerniera a molla, avvitabile



ACL-APB

Sistema di chiusura, Ferpporta magnetico



SLB

Pistoncino a molla, acciaio classe 5.8



ATZY

Antivibrante elastico sgolato, Acciaio

**Prodotti correlati**