



Idler sprocket for plate chain

For chain ranges 821 and 805



PR821

- For use with CAP821 and CAP805 plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

Easy assembly

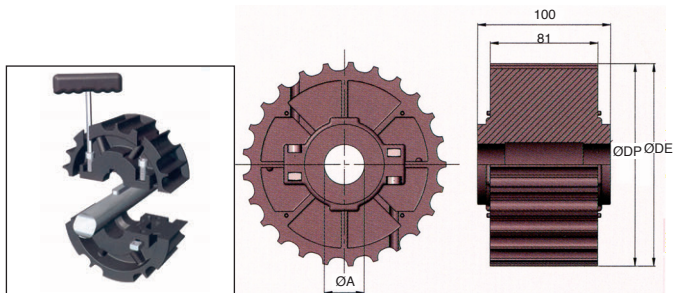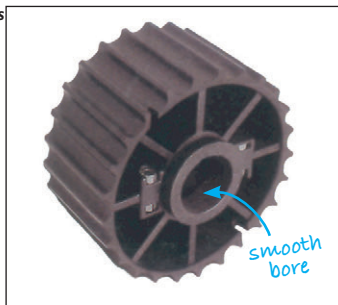

Two part design

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR821-25-30	25	153	153,2	30	0,9	70,12 €
PR821-25-35	25	153	153,2	35	0,9	70,12 €
PR821-25-40	25	153	153,2	40	0,9	70,12 €
PR821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

Altri prodotti...



CFS
Perno folle mini,
Miniatura



M0
Coppia ruota e vite
senza fine , Acciaio
non temprato



AT5-25ECO
Puleggia dentata di
posizionamento tipo
AT, Serie economica -
AT5 al...



PR85
Piede fissabile con
snodo - poliammide, Ø
83



PTMR
Telescopic furniture
foot, threaded stud



SER
Accessori per porte,
Fermaporte a
calamita



LWL
Guida lineare a sfere -
Sfere inox, Binario -
da 514 N a 16700 N



PM4
Coppia ruota e vite
senza fine, Bronzo



PCLA_M
Maniglia a ripresa -
femmina, Plastica



UCP_SS
Cuscinetto ritto tutto
inox, Inox



SHSS
Vite a spalla inox 416,
Inox 416 pretrattato



HK
Accessorio di
serraggio manuale,
Serraggio manuale T

Prodotti correlati