



Idler sprocket for plate chain

For chain ranges 821 and 805


PR821

- For use with CAP821 and CAP805 plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

Easy assembly

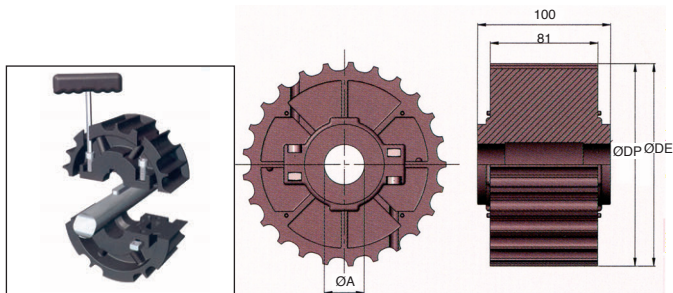

Two part design

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request


Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR821-25-30	25	153	153,2	30	0,9	70,12 €
PR821-25-35	25	153	153,2	35	0,9	70,12 €
PR821-25-40	25	153	153,2	40	0,9	70,12 €
PR821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

Altri prodotti...



Manopola a pressione,
PVC nero

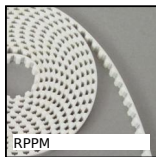

Cinghia aperta al
metro tipo RPP, RPP5
Poliuretano armatura
in acciaio




Visualizzatore
multifunzione,
Supporto - montaggio
ortogonale



Tappo per tubo, Con
inserto maschiato



Limitatore di coppia
ad attrito Vari-Tork®,
0.53 a 1.32 Nm

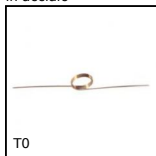

Molla di torsione, Inox



Martinetto a vite - Vite
rotante, Con
madrevite esterna



Guarnizione in
gomma, Da
agganciare



Rondella girevole, Vite
con spalla a testa



Cavallotto Inox, Inox



Ruota girevole a foro
centrale, Inox -



Guida mini Drylin® N,
Rail end cap

Prodotti correlati