

# Idler sprocket for plate chain



## PR880


## For chain range 880 TAB

- For use with CAP880T plate chains
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


### Advantage

- Two part design facilitates easy assembly

**Easy assembly**

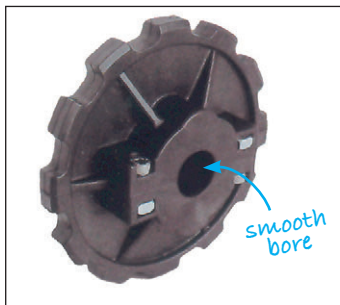

Two part design

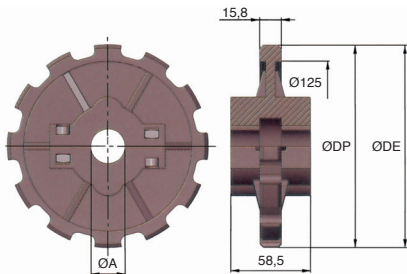

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR880-12-25	12	147,2	147,21	25	0,39	25,38 €
PR880-12-30	12	147,2	147,21	30	0,39	25,38 €
PR880-12-35	12	147,2	147,21	35	0,39	25,38 €
PR880-12-40	12	147,2	147,21	40	0,39	25,38 €

Dimensions in mm

## Altri prodotti...



EAR  
Cuscinetti a sfere -  
Accessorio, Ghiera  
autobloccante - anello  
di fr...



CMA  
Vite ad occhio,  
Acciaio




G-ECO15  
Ingranaggio dritto  
acciaio - serie ECO,  
Acciaio C45



RFK48B  
Riduttore ipoide inox,  
fino a 350 Nm



UGH20  
Unità di guida tipo H,  
Per martinetti Ø20

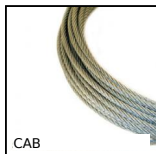

CAB  
Cavo di fissaggio,  
Acciaio galvanizzato



CHMX\_CHMDX  
Albero per riduttore a  
ruota e vite senza fine  
CHMR e CHM, Albero  
se...




HTD8M\_30  
Puleggia dentata di  
trasmissione tipo  
HTD, HTD8 Ghisa



BPMc  
Pressore a molla con  
intaglio e puntale a



PSG1  
Ingranaggio dritto di  
precisione, Acciaio

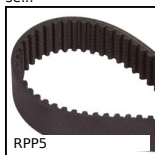

RPP5  
Cinghia di  
trasmissione RPP,



PHTss  
Maniglia a ponte, Fino  
a 250°C

## Prodotti correlati



CAP880  
Catena a tapparella,  
Stretta serie 880



PT880  
Pignone di trazione,  
Serie 880



BAP25  
Anello di bloccaggio,  
Ø25 - Ø40



BAP  
Anello di bloccaggio,  
Ø10 - Ø20