

Idler sprocket for plate chain



PR880


For chain range 880 TAB

- For use with CAP880T plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

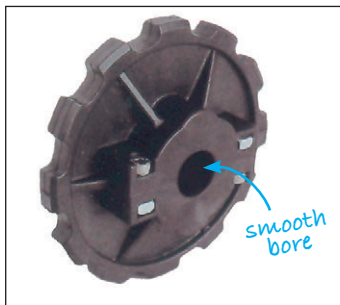

Two part design

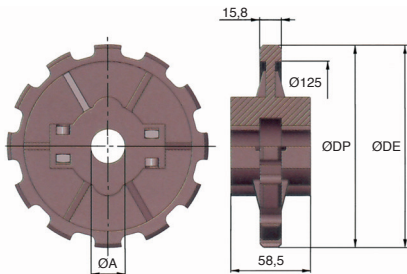

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR880-12-25	12	147,2	147,21	25	0,39	25,38 €
PR880-12-30	12	147,2	147,21	30	0,39	25,38 €
PR880-12-35	12	147,2	147,21	35	0,39	25,38 €
PR880-12-40	12	147,2	147,21	40	0,39	25,38 €

Dimensions in mm

Altri prodotti...



BH01

Cuscinetto radiale flangiato, Montaggio : pressione e colla



SVR5

Martinetto a vite - Vite rotante, Con madrevite esterna



CABtool

Attrezzi per cavi, Attrezzi per crimpatura



PRF-CHAR-POU

Attrezzi, Carrello attrezzi



EX

Albero per riduttori E, Albero doppio per riduttori E



JCDss

Giunto cardanico - inox, Sollecitazioni leggere



PRS80

Piede snodato tutto inox Ø80, Ø 80



G0

Ingranaggio dritto acciaio, Acciaio 20NCD2



CHA_GC_14SS

Cerniera a bandiera inox, Ad avvitare




UCFL

Cuscinetto a flangia ovale in ghisa, Ghisa



CHAK

Cerniera, Hi-Klik™ - di posizionamento

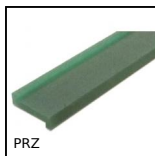

PRZ

Profilo supporto per catena, Profilo a Z da posare

Prodotti correlati



CAP880

Catena a tapparella, Stretta serie 880



PT880

Pignone di trazione, Serie 880



BAP25

Anello di bloccaggio, Ø25 - Ø40



BAP

Anello di bloccaggio, Ø10 - Ø20