

Idler sprocket for plate chain



PR880


For chain range 880 TAB

- For use with CAP880T plate chains
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

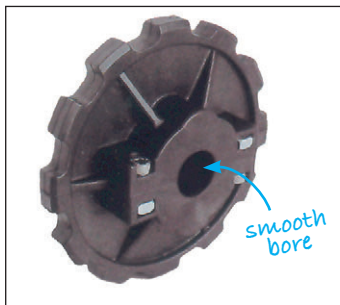

Two part design

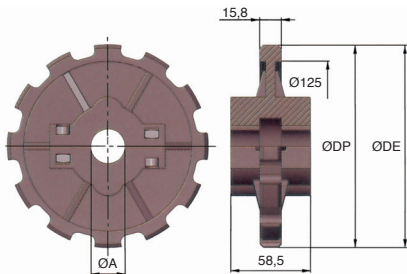

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR880-12-25	12	147,2	147,21	25	0,39	25,38 €
PR880-12-30	12	147,2	147,21	30	0,39	25,38 €
PR880-12-35	12	147,2	147,21	35	0,39	25,38 €
PR880-12-40	12	147,2	147,21	40	0,39	25,38 €

Dimensions in mm

Altri prodotti...



Q4
Cuscinetto a doppia corona di sfere, Radiale - Acciaio



DBL821
Rotella per catena, Serie 821



MCL
Manicotto cilindrico maschiato, Cilindrico - acciaio



AT5P_AT10P
Piastra di giunzione per cinghia AT, AT10



SR
Cremagliera sezione stretta, Inox



GLT3E-50
Guide telescopiche acciaio, Estensione extra



RFK28B
Riduttore ipoide inox, fino a 130 Nm



BAP25
Anello di bloccaggio, Ø25 - Ø40



LSAG
Albero scanalato a sfere, Carello - da 514



MCL
Manicotto cilindrico maschiato, Cilindrico -



PSG35
Ingranaggio dritto di precisione, Inox 303



ATZY
Antivibrante elastico sgolato, Acciaio

Prodotti correlati



CAP880
Catena a tapparella, Stretta serie 880



PT880
Pignone di trazione, Serie 880



BAP25
Anello di bloccaggio, Ø25 - Ø40



BAP
Anello di bloccaggio, Ø10 - Ø20