

# Idler sprocket for plate chain



## PR880


## For chain range 880 TAB

- For use with CAP880T plate chains
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


### Advantage

- Two part design facilitates easy assembly

**Easy assembly**

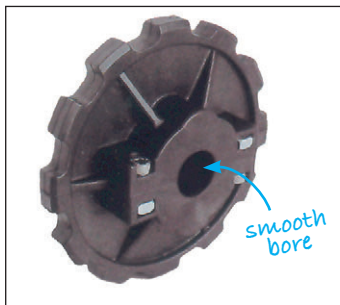

Two part design

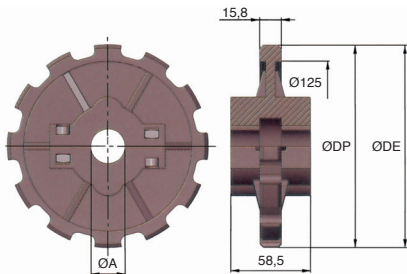

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR880-12-25	12	147,2	147,21	25	0,39	25,38 €
PR880-12-30	12	147,2	147,21	30	0,39	25,38 €
PR880-12-35	12	147,2	147,21	35	0,39	25,38 €
PR880-12-40	12	147,2	147,21	40	0,39	25,38 €

Dimensions in mm

## Altri prodotti...



KKB-AR

Manicotto a sfere inclinate, Carichi standard / -20° +200°



RURp

Ruota girevole a doppio bloccaggio, Poliuretano - Mozzo alluminio (U...



JCDss

Giunto cardanico - inox, Sollecitazioni leggere




HAR9

Rondella girevole, DIN 6371



PSG25S

Ingranaggio dritto di precisione, Inox 303

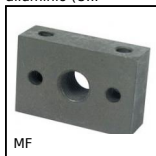

MF

Deceleratore, Flangia rettangolare



UGH16

Unità di guida tipo H, Per martinetti Ø12 e Ø16



PRF4590\_E

Squadra di giunzione, PRF4590



ACLCHAR

Cerniera ad avvitare, Con fori oblunghi



PW\_PWG1

Vite senza fine di precisione, Acciaio



HTD5M\_25

Puleggia dentata di trasmissione tipo HTD, HTD5 Alluminio



ASH

Anello di sollevamento, dritto a saldare

## Prodotti correlati



CAP880

Catena a tapparella, Stretta serie 880



PT880

Pignone di trazione, Serie 880



BAP25

Anello di bloccaggio, Ø25 - Ø40



BAP

Anello di bloccaggio, Ø10 - Ø20