



Idler sprocket for plate chain

For chain range 881 TAB

PR881

- For use with CAP881T/SS plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,
please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

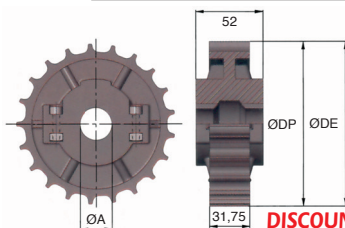

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR881-21-25	21	129	129,26	25	0,37	27,79 €
PR881-21-30	21	129	129,26	30	0,37	27,79 €
PR881-21-35	21	129	129,26	35	0,37	27,79 €
PR881-21-40	21	129	129,26	40	0,37	27,79 €
PR881-21-45	21	129	129,26	45	0,37	27,79 €
PR881-23-25	23	141	141,22	25	0,44	28,85 €
PR881-23-30	23	141	141,22	30	0,44	28,85 €
PR881-23-35	23	141	141,22	35	0,44	28,85 €
PR881-23-40	23	141	141,22	40	0,44	28,85 €
PR881-23-45	23	141	141,22	45	0,44	28,85 €
PR881-25-25	25	153	153,20	25	0,49	30,30 €
PR881-25-30	25	153	153,20	30	0,49	30,30 €
PR881-25-35	25	153	153,20	35	0,49	30,30 €
PR881-25-40	25	153	153,20	40	0,49	30,30 €
PR881-25-45	25	153	153,20	45	0,49	30,30 €

Dimensions in mm

Altri prodotti...



Manopola, Zigrinata - Cieco



Chiusura a leva regolabile, Corsa da 82mm a 92mm



Giunto senza gioco Rotex® GS, da 0.5 a 190Nm



Piede fissabile con base lamiera Ø100, Ø 100



Ruota per vite senza fine, Bronzo



Testa a snodo maschio DIN ISO12240-4, Acciaio / bronzo




Ingran. dritto di precisione trattato skiving, Acciaio 20NCD2 cement...



Ingranaggio dritto PRESTAZIONE, Acciaio 35NCD6




Pistoncino a molla, Da saldare - Acciaio

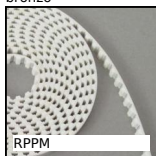

Cinghia aperta al metro tipo RPP, RPP14



Perno di bloccaggio tipo ¼ di giro, ¼ di

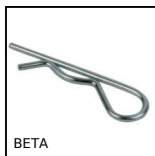

Copiglia beta, Beta

Prodotti correlati



Catena a tapparella, Stretta serie 881



Pignone di trazione, Serie 881