



# Idler sprocket for plate chain

For chain range 881 TAB

PR881

- For use with CAP881T/SS plate chains
- Materials:  
Reinforced polyamide  
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,  
please refer to technical pages


## Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

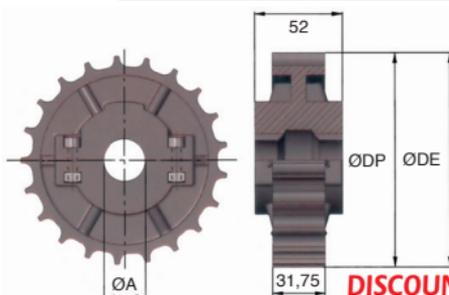

## DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR881-21-25	21	129	129,26	25	0,37	27,79 €
PR881-21-30	21	129	129,26	30	0,37	27,79 €
PR881-21-35	21	129	129,26	35	0,37	27,79 €
PR881-21-40	21	129	129,26	40	0,37	27,79 €
PR881-21-45	21	129	129,26	45	0,37	27,79 €
PR881-23-25	23	141	141,22	25	0,44	28,85 €
PR881-23-30	23	141	141,22	30	0,44	28,85 €
PR881-23-35	23	141	141,22	35	0,44	28,85 €
PR881-23-40	23	141	141,22	40	0,44	28,85 €
PR881-23-45	23	141	141,22	45	0,44	28,85 €
PR881-25-25	25	153	153,20	25	0,49	30,30 €
PR881-25-30	25	153	153,20	30	0,49	30,30 €
PR881-25-35	25	153	153,20	35	0,49	30,30 €
PR881-25-40	25	153	153,20	40	0,49	30,30 €
PR881-25-45	25	153	153,20	45	0,49	30,30 €

Dimensions in mm

## Altri prodotti...



PSG155  
Ingranaggio dritto di precisione, Inox 316



M1  
Vite senza fine, Acciaio temprato



FTSN  
Albero supportato per guida lineare, Albero acciaio / supporto allu...



ETGamme  
Molla di trazione DIN2097, DIN 2097



MDB\_MTB  
Ingranaggio conico in plastica stampata , 3:1



SER69K  
Chiusura 1/4 di giro per agroalimentare, Inox



RHTccs  
Ruota alte temperature, fino a 200kg



EV  
Terminale rapido inox per cavi,



NPTF20  
Morsetto di collegamento, Fisso Ø10 a Ø14



YG2  
Ingranaggio dritto PRESTAZIONE, Acciaio 35NCD6



UGH32  
Unità di guida tipo H, Per martinetti Ø 32



ASH  
Anello di sollevamento, dritto a saldare

## Prodotti correlati



CAP881  
Catena a tapparella, Stretta serie 881



PT881  
Pignone di trazione, Serie 881