



# Idler sprocket for plate chain

For chain range 881 TAB

PR881

- For use with CAP881T/SS plate chains
- Materials:  
Reinforced polyamide  
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,  
please refer to technical pages


## Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

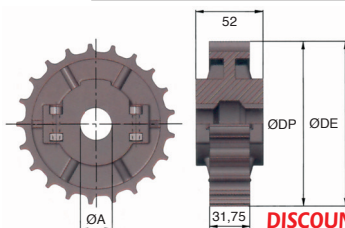

## DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR881-21-25	21	129	129,26	25	0,37	27,79 €
PR881-21-30	21	129	129,26	30	0,37	27,79 €
PR881-21-35	21	129	129,26	35	0,37	27,79 €
PR881-21-40	21	129	129,26	40	0,37	27,79 €
PR881-21-45	21	129	129,26	45	0,37	27,79 €
PR881-23-25	23	141	141,22	25	0,44	28,85 €
PR881-23-30	23	141	141,22	30	0,44	28,85 €
PR881-23-35	23	141	141,22	35	0,44	28,85 €
PR881-23-40	23	141	141,22	40	0,44	28,85 €
PR881-23-45	23	141	141,22	45	0,44	28,85 €
PR881-25-25	25	153	153,20	25	0,49	30,30 €
PR881-25-30	25	153	153,20	30	0,49	30,30 €
PR881-25-35	25	153	153,20	35	0,49	30,30 €
PR881-25-40	25	153	153,20	40	0,49	30,30 €
PR881-25-45	25	153	153,20	45	0,49	30,30 €

Dimensions in mm


## Altri prodotti...



ACLLPP  
Sistema di chiusura,  
Chiusura a molla



UGPC  
Unità di guida per  
cilindrico, Cuscinetto  
corto

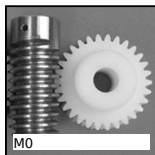

M0  
Coppia ruota e vite  
senza fine , Plastica  
lavorata (delrin)



HCV  
Sistema di guida su  
binario a V Simple  
Select®, con carrello



UCFL  
Cuscinetto a flangia  
ovale in ghisa, Ghisa



GET-AL  
Giunto elastico  
alluminio serie eco.,  
Alluminio



HTD5M\_15  
Puleggia dentata di  
trasmissione tipo  
HTD, HTD5 Alluminio



GLP  
Volantino a 6 lobi,  
Tecnopolimero -  
Acciaio



BPL  
Sfera portante con  
flangia, Leggero



SDC  
Boccole di  
posizionamento per



LR  
Cuscinetti a sfere -  
Accessorio, Ghiera di



Q6  
Cuscinetto radiale a  
sfere, Acciaio

## Prodotti correlati



CAP881  
Catena a tapparella,  
Stretta serie 881



PT881  
Pignone di trazione,  
Serie 881