



Idler sprocket for plate chain

For chain range 881 TAB

PR881

- For use with CAP881T/SS plate chains

- Materials:

Reinforced polyamide

Stainless steel screws

- Operating temp.: -10°C to +120°C

- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

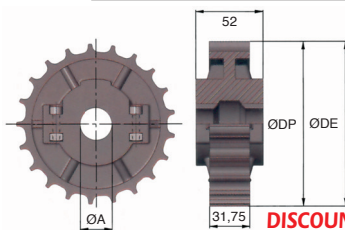

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR881-21-25	21	129	129,26	25	0,37	27,79 €
PR881-21-30	21	129	129,26	30	0,37	27,79 €
PR881-21-35	21	129	129,26	35	0,37	27,79 €
PR881-21-40	21	129	129,26	40	0,37	27,79 €
PR881-21-45	21	129	129,26	45	0,37	27,79 €
PR881-23-25	23	141	141,22	25	0,44	28,85 €
PR881-23-30	23	141	141,22	30	0,44	28,85 €
PR881-23-35	23	141	141,22	35	0,44	28,85 €
PR881-23-40	23	141	141,22	40	0,44	28,85 €
PR881-23-45	23	141	141,22	45	0,44	28,85 €
PR881-25-25	25	153	153,20	25	0,49	30,30 €
PR881-25-30	25	153	153,20	30	0,49	30,30 €
PR881-25-35	25	153	153,20	35	0,49	30,30 €
PR881-25-40	25	153	153,20	40	0,49	30,30 €
PR881-25-45	25	153	153,20	45	0,49	30,30 €

Dimensions in mm

Altri prodotti...



AT5courroie

Cinghia chiusa
posizionamento AT,
AT5 Poliuretano
armatura in acciaio




TS01_TW01

Guida lineare su
binario Drylin® T, fino
al 7000 N



DH

Spina cilindrica,
standard DIN 6325

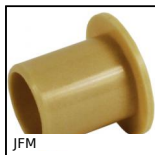

JFM

Cuscinetto a collare ,
Polimero universale



BLHM50

Rinvio angolare, fino a
30 Nm



FDSQ

Flexible drive shaft,
Masterflex® Steel,
with PVC casing



DOMI30

Slitta di regolazione
Domino 30, Slitta
DOMILINE 30 con
contatore e ...



CCLSS

Capocorda ad
occhiello, Inox



HK

Accessorio di
serraggio manuale,
Serraggio manuale T



RURp

Ruota girevole a
doppio bloccaggio,
Poliuretano - Mozzo



WBGV

Anello di
sollevamento, Con
grillo ad avvitare



PF30NM

Riduttore a ruota e
vite senza fine, fino a
8.8 Nm

Prodotti correlati



CAP881

Catena a tapparella,
Stretta serie 881



PT881

Pignone di trazione,
Serie 881