

Idler sprocket for plate chain



PR882


For chain range 882 TAB

- For use with CAP882T plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

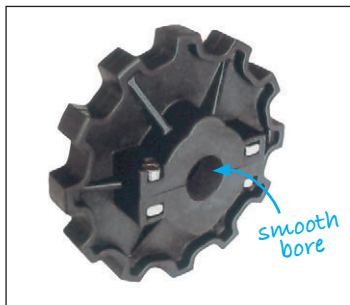

Two part design

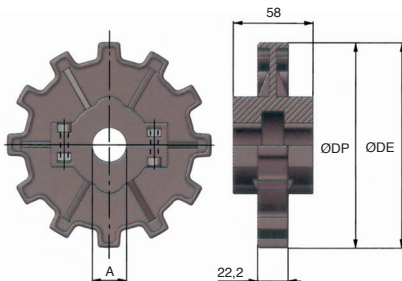

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR882-12-25	12	148,5	147,2	25	0,38	29,36 €
PR882-12-30	12	148,5	147,2	30	0,38	29,36 €
PR882-12-35	12	148,5	147,2	35	0,38	29,36 €
PR882-12-40	12	148,5	147,2	40	0,38	29,36 €
PR882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

Altri prodotti...



CHB

Riduttore a ruota e vite senza fine, fino a 41 Nm



ACL-PR

Elementi di giunzione, Collegamento a 90°



METC

Cuscinetto a collare, Bronzo autolubrificante



T39_T49

Molla di trazione al metro acciaio, al metro



PITA

Pistoncino a molla, con maniglia a T



HW_HT

Guida su semi-binari, Binario



PW_PWG3

Vite senza fine di precisione, Inox



VELM6

Supporto avvitabile per rotolo a strappo fermacavi, Poliammide



CHAGC-AL

Cerniera ad avvitare, Sfilabile



HS

Distanziatore esagonale, Inox 303



SLB

Pistoncino a molla, inox



GG2

Ingranaggio dritto rettificato, Acciaio trattato

Prodotti correlati



CAP882

Catena a tapparella, Larga serie 882



PT882

Pignone di trazione, Serie 882