

# Idler sprocket for plate chain



## PR882

## For chain range 882 TAB

- For use with CAP882T plate chains
- Materials:  
Reinforced polyamide  
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


### Advantage

- Two part design facilitates easy assembly

**Easy assembly**



Two part design

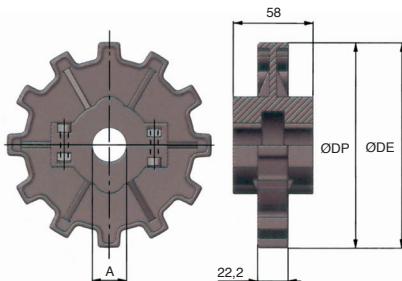

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR882-12-25	12	148,5	147,2	25	0,38	29,36 €
PR882-12-30	12	148,5	147,2	30	0,38	29,36 €
PR882-12-35	12	148,5	147,2	35	0,38	29,36 €
PR882-12-40	12	148,5	147,2	40	0,38	29,36 €
PR882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

## Altri prodotti...



RTE  
Rotex®, elastico,  
acciaio



SH2  
Ingranaggio elicoidale  
ad assi paralleli,  
Acciaio 20NCD2



PFM  
Piede senza snodo,  
Lamiera modellata



PM3  
Coppia ruota e vite  
senza fine, Plastica  
lavorata (delrin)




SVG  
Chiusura a leva  
regolabile, Corsa da  
106,7mm a 121,4mm



CHAsb89  
Cerniera senza perno,  
Cerniera in polimero




J65  
Riduttore coassiale a  
treni paralleli, da 0.80  
a 2.95 - a treni para...

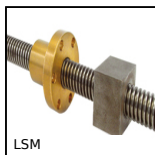

LSM  
Vite trapezoidale inox  
316L, Inox - 1 filetto



CHA225  
Cerniera ad avvitare,  
225 gradi

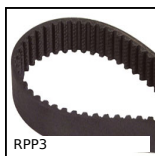

RPP3  
Cinghia di  
trasmissione RPP,  
RPP3



PPS  
Anello di  
sollevamento, Gancio  
universale ad avvitare



FBL6000\_K1  
Spazzola al metro  
fibre PA6 da Ø0,2 a  
Ø0,3, Poliammide  
nero 6 - pi...

## Prodotti correlati



CAP882  
Catena a tapparella,  
Larga serie 882



PT882  
Pignone di trazione,  
Serie 882