

Idler sprocket for plate chain



PR882

For chain range 882 TAB

- For use with CAP882T plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

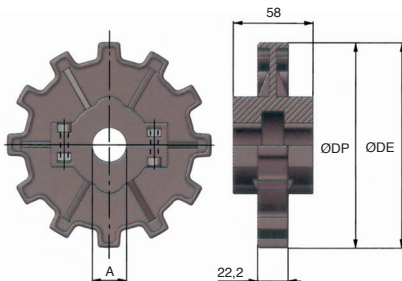

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR882-12-25	12	148,5	147,2	25	0,38	29,36 €
PR882-12-30	12	148,5	147,2	30	0,38	29,36 €
PR882-12-35	12	148,5	147,2	35	0,38	29,36 €
PR882-12-40	12	148,5	147,2	40	0,38	29,36 €
PR882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

Altri prodotti...



TRM

Crema di acciaio con sezione circolare, Acciaio - modulo 1-6



PM3

Ruota per vite senza fine, Bronzo



E20

Riduttore a rinvio angolare, da 0.60 a 3.84 Nm



NIN

Dado autofrenante, Acciaio



PSG25

Ingranaggio dritto di precisione, Acciaio 20NCD2 cementato temprato



CHA_GC_145S

Cerniera a bandiera inox, Ad avvitare



PGMT

Maniglia a ponte a fissaggio anteriore, Inox



DEP

Attrezzi Hygienic Usit® and Hygienic Design®, Inserto di protezione...



CHA1056_U20

Cerniera ad avvitare, Sezione 90X60



RNAST

Rotelle, Senza anello interno



PW_PWG25

Vite senza fine di precisione, Acciaio



LSAG

Albero scanalato a sfere, Binario - da 514 N a 15386 N

Prodotti correlati



CAP882

Catena a tapparella, Larga serie 882



PT882

Pignone di trazione, Serie 882