

Idler sprocket for plate chain



PR882

For chain range 882 TAB

- For use with CAP882T plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,
please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

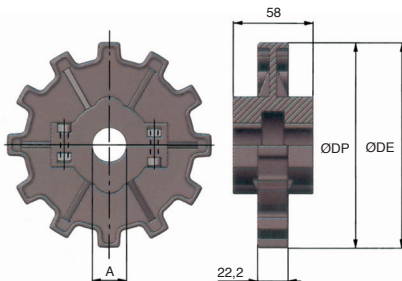

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR882-12-25	12	148,5	147,2	25	0,38	29,36 €
PR882-12-30	12	148,5	147,2	30	0,38	29,36 €
PR882-12-35	12	148,5	147,2	35	0,38	29,36 €
PR882-12-40	12	148,5	147,2	40	0,38	29,36 €
PR882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

Altri prodotti...



BZY
Antivibrante elastico cilindrico, Acciaio



LVT
Mini martinetto motorizzato 1A, 1 ampere



PRF_PL_4590
Elementi di giunzione, Piastra di giunzione - 45x90 mm



HK
Accessorio di serraggio manuale, Serraggio manuale T



G3-ECO
Ingranaggio dritto acciaio - serie ECO, Acciaio C45



ZG0
Ingranaggio dritto in plastica, Plastica lavorata (delrin)



ZHG5
Ingranaggio dritto in plastica, Plastica lavorata (delrin)



GCH
Guida lineare a sfere Eco, economica




PRES3HR
Pressa manuale da banco, Pressione fino a 400kg



BABtss
Perno autobloccante inox 303, Inox 303



R206
Molla per stampi ISO10243, Extra-forte

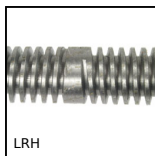

LRH
Vite trapezoidale a doppia inclinazione, a doppia inclinazione - 1 f...

Prodotti correlati



CAP882
Catena a tapparella, Larga serie 882



PT882
Pignone di trazione, Serie 882