

Idler sprocket for plate chain



PR882


For chain range 882 TAB

- For use with CAP882T plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

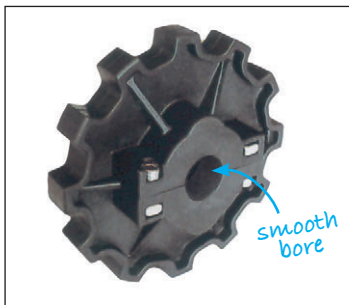

Two part design

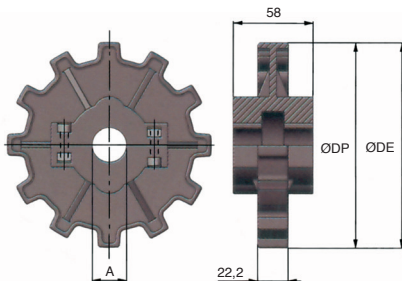

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty. | 1+ | 5+ | 10+ |
| Disc. | List | -5% | On request |

| Part number | No. of teeth | ØDE | ØDP | Bore ØA | Weight (kg) | Price each 1 to 4 |
|-------------|--------------|-------|-------|---------|-------------|-------------------|
| PR882-12-25 | 12 | 148,5 | 147,2 | 25 | 0,38 | 29,36 € |
| PR882-12-30 | 12 | 148,5 | 147,2 | 30 | 0,38 | 29,36 € |
| PR882-12-35 | 12 | 148,5 | 147,2 | 35 | 0,38 | 29,36 € |
| PR882-12-40 | 12 | 148,5 | 147,2 | 40 | 0,38 | 29,36 € |
| PR882-12-45 | 12 | 148,5 | 147,2 | 45 | 0,38 | 29,36 € |

Dimensions in mm

Altri prodotti...



HTD5M_15
Puleggia dentata di trasmissione tipo HTD, HTD5 Alluminio



R205
Molla per stampi ISO10243, Forte



SBF
Sealed flange bearing unit for Food Industry, cover



FGWA
Supporto per estremità dell'albero, A soletta



M1
Coppia ruota e vite senza fine, Acciaio temprato



E40
Riduttore a rinvio angolare, da 2.30 a 20 Nm



INS_SS
Boccola autofrettante Inox, Inox



Q6
Cuscinetto radiale a sfere, Acciaio



RTT
Calettatore di bloccaggio, Coppia



RDE-B
Ridondella di tenuta Hygienic Usit®,



BPH
Sfera portante a incastro cilindrico,



RFK48B
Riduttore ipoide inox, fino a 350 Nm

Prodotti correlati



CAP882
Catena a tapparella, Larga serie 882



PT882
Pignone di trazione, Serie 882