

# Idler sprocket for plate chain



## PR882

## For chain range 882 TAB

- For use with CAP882T plate chains
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


### Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

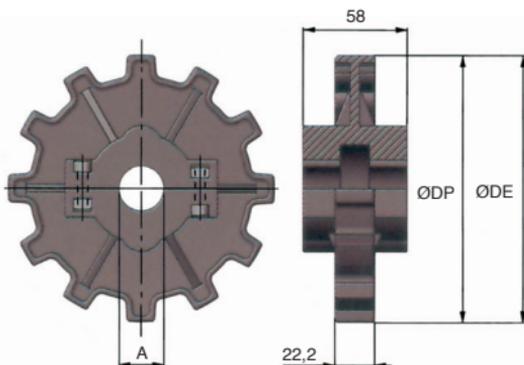

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR882-12-25	12	148,5	147,2	25	0,38	29,36 €
PR882-12-30	12	148,5	147,2	30	0,38	29,36 €
PR882-12-35	12	148,5	147,2	35	0,38	29,36 €
PR882-12-40	12	148,5	147,2	40	0,38	29,36 €
PR882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

## Altri prodotti...



GBMF

Dado per vite a sfere,  
Dado flangiato a  
circuiti multipli



BSM

Pressore a molla con  
esagono incassato,  
corpo e spina inox  
303



SSDB

Ingranaggio conico  
inox, 2:1




CHA138

Cerniera ad avvitare,  
138 gradi



PCF4

Supporto antivibrante  
cabina conico, Piastra  
a base quadrata

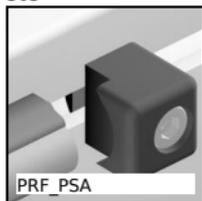

PRF\_PSA

Rotella per profilo  
alluminio, per  
bloccaggio albero



BLH60

Rinvio angolare a L,  
da 19 a 70 Nm



PP60

Riduttore a ruota e  
vite senza fine, da  
17.80 a 34 Nm



PM3

Vite senza fine,  
Acciaio non temprato



CMAss

Vite ad occhio, Inox



VEL

Rotolo a strappo  
fermacavi, cavi



ZBconique

Ingranaggio conico in  
plastica, 1:1

## Prodotti correlati



CAP882

Catena a tapparella,  
Larga serie 882



PT882

Pignone di trazione,  
Serie 882