

PRES

Accessories for PRES-3HR and PRES-4HR presses

These accessories are only suitable for use with the PRES-3HR and PRES-4HR presses


PRES-PMB: Micrometric adjustment PMB.
Bottom dead centre adjustment system, graduated every 0.02 mm

PRES-TE: Slot nuts for securing tools in the T slot

PRES-ER25: Collet chuck
Collet chuck with ER25 collet for shanks from \varnothing 1.5 to \varnothing 16 mm (Other diameters between 1.5 and 16 mm available on request)



PRES-PMB

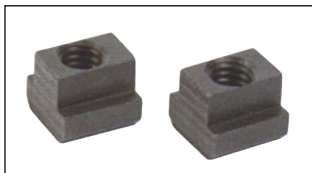

PRES-TE



PRES-ER25

DISCOUNTS

Qty	1	2+	4+
Disc.	List	-3%	On request

Part number	Type	For shank diameter	Price each
PRES-PMB	Micrometric adjustment (0.02mm)	-	403,32 €
PRES-TE	Set of slot nuts for T profile slots	-	26,30 €
PRES-ER25-1.5	tool holder	1,5	467,62 €
PRES-ER25-2	tool holder	2	467,62 €
PRES-ER25-4	tool holder	4	467,62 €
PRES-ER25-6	tool holder	6	467,62 €
PRES-ER25-8	tool holder	8	467,62 €
PRES-ER25-10	tool holder	10	467,62 €
PRES-ER25-12	tool holder	12	467,62 €
PRES-ER25-14	tool holder	14	467,62 €
PRES-ER25-16	tool holder	16	467,62 €

Dimensions in mm

Altri prodotti...



D-PAR_SS
Piedino antivibrante
parabolico, inox



AT5M_AT10M
Cinghia aperta al
metro tipo AT, AT10
Poliuretano armatura
in acciaio



SH0
Ingranaggio elicoidale
ad assi paralleli,
Plastica lavorata
(delrin)



HW_HT
Guida su semi-binari,
Ruota



MDPOT
Potenziometro,



PRS80
Piede snodato tutto
inox Ø80, Ø 80




RFK48B
Riduttore ipoide inox,
fino a 350 Nm



DOMI30
Kit di raccordo, Kit di
raccordo XZ



TOL
Testa orientabile,
Lunga

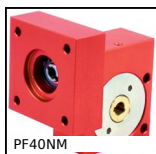

PF40NM
Riduttore a ruota e
vite senza fine, fino a
18 Nm



SHS
Vite a spalla inox 303,
Inox 303



F7-P-AM
Visualizzatore
multifunzione, Anello
magnetico

Prodotti correlati



PRES2HR
Pressa manuale da
banco, Pressione fino
a 200kg



PRES3HR
Pressa manuale da
banco, Pressione fino
a 400kg



PRES4HR
Pressa manuale da
banco, Pressione fino
a 600kg