

Tool holder for aluminium profile

New

PRFCHARPOU **MiniTec** Runs in channel

- For supporting tools on a workstation

- Materials:

Stainless steel

Grey ABS wheels


Assembly

- Mount the carrier on the aluminium profile



- If necessary, the bottom wheel can be temporarily removed during assembly

Info

- Use with PRF4532-3

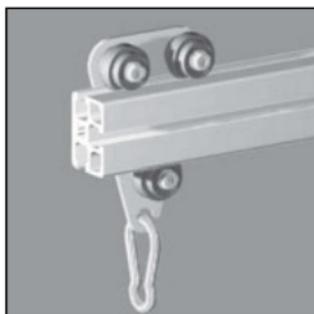

Typical application

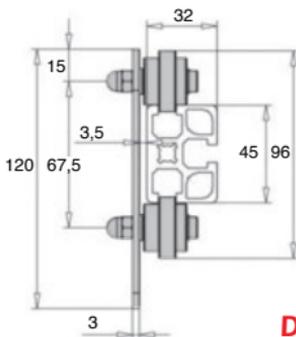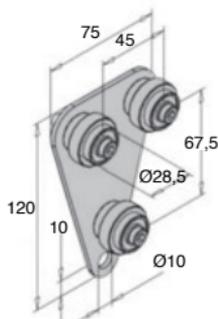

DISCOUNTS

| | | | |
|------------|-----|------------|------|
| Qty | 1+ | 50+ | 100+ |
| Disc. List | -5% | On request | |

| Part number | Maximum load (kg) | Weight (g) | Price each 1 to 49 |
|--------------|-------------------|------------|--------------------|
| PRF-CHAR-POU | 40 | 263,1 | 73,83 € |

Dimensions in mm

Altri prodotti...



CFF_SS
Testa a snodo
femmina DIN
ISO12240-4, Inox /
bronzo - Serie



BTCW
Tappo inox per tubo
quadrato, A saldare



RHTplss
Ruota alte
temperature, fino a
200kg



BAP
Anello di bloccaggio,
Ø10 - Ø20



MAX22
Motoriduttore DC 12V
e 24V DC, da 0,07 a
0,2Nm



E60B
Riduttore a rinvio
angolare, da 4.50 a
24 Nm



VELprf
Supporto clip per
rotolo a strappo
fermacavi,
Poliammide



M
Manicotto per giunto
cardanico, Accessori



HBM
Guida su semi-binari,
Boccola di regolazione



PTA150
Piede snodato con
base stampata Ø150,
40000N



DB
Ingranaggio conico -
Acciaio 60C40, 2:1



PNA_R
Giunto elastico
PERIFLEX, Collare di
ricambio

Prodotti correlati



PRF4532
Profilato alluminio
standard, 45 x 32 mm