

Guide for aluminium profile

PRFGPA **MiniTec**

Parallel rails




- **Parallel guides for PRF profiles**
- Full edge-to-edge movement
- Length 2 metres
- Materials:
Hard plastic, black

Advantages

- Does not change overall height
- Particularly wear-resistant

Mounting

- If necessary, fix on one side with M6x16 screws (machining on the aluminium profile and on the rail required)

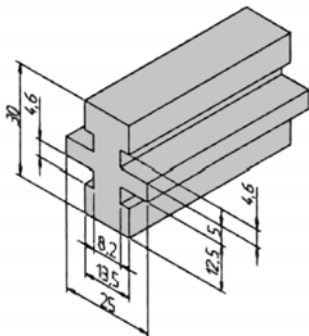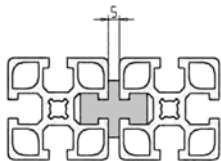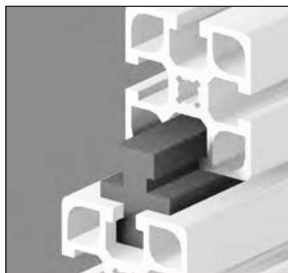

DISCOUNTS

| | | | |
|------|-----|-----|------------|
| Qty | 1+ | 5+ | 10+ |
| Disc | Net | -5% | On request |

| Part N° | L | Weight (g/m) | Price each |
|-----------|------|--------------|------------|
| PRF-GPA-2 | 2000 | 387 | 41,40 € |

All dimensions in mm

Altri prodotti...



T25-6ECO

Puleggia dentata di posizionamento tipo T, Serie economica - T2.5 al...



SHW

Rondella semplice, Acciaio



DB

Ingranaggio conico - Acciaio 60C40, 2:1



STU

Boccola a sfere lineare e rotativa, Acciaio



CHAuss

Cerniera ad avvitare, 270°



G0

Ingranaggio dritto acciaio, Acciaio 20NCD2



ACL

Elementi di giunzione, Angolare semicircolare



PR821

Ruota di rinvio, Serie 821 e 805



ACLEPP

Angolare, 4 fori



BSM_LOK

Pressore a molla con esagono incassato, LONG-LOK - corpo in



FBL6000_K1

Spazzola al metro fibre PA6 da Ø0,2 a Ø0,3, Poliammide



SC2

Giunto rigido in 2 parti, Ganascia di serraggio

Prodotti correlati



PRF-GPB

Guide for aluminium profile, Rail for 8mm wide slots



PRF4545

Profilato alluminio standard, 45 x 45 mm