

Guide for aluminium profile

PRFGPA **MiniTec**

Parallel rails




- **Parallel guides for PRF profiles**
- Full edge-to-edge movement
- Length 2 metres
- Materials:
Hard plastic, black

Advantages

- Does not change overall height
- Particularly wear-resistant

Mounting

- If necessary, fix on one side with M6x16 screws (machining on the aluminium profile and on the rail required)

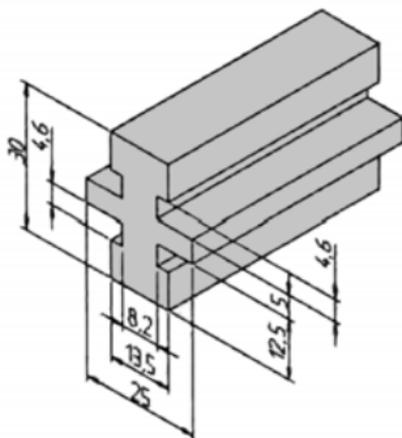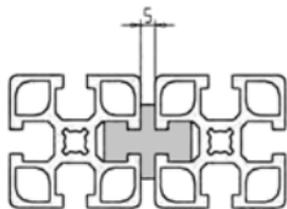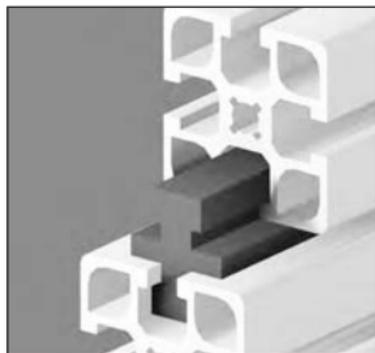

DISCOUNTS

Qty	1+	5+	10+
Disc	Net	-5%	On request

Part N°	L	Weight (g/m)	Price each
PRF-GPA-2	2000	387	41,40 €

All dimensions in mm

Altri prodotti...



HTD14M_55

Puleggia dentata di trasmissione tipo HTD, HTD14 Ghisa



UCF

Cuscinetto a flangia quadrata in ghisa, Ghisa



ACLAPA

Sistema di chiusura, Battuta a calamita



D-PAR_SS

Piedino antivibrante parabolico, inox




BLH70

Rinvio angolare a L, da 26 a 128 Nm



GG1

Ingranaggio dritto rettificato, Acciaio trattato

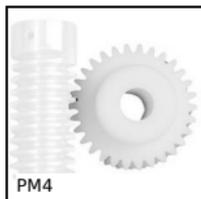

PM4

Ruota per vite senza fine, Plastica lavorata (delrin)



NCT_AT

Giunto di collegamento, Ad angolo variabile




LVT

Mini martinetto motorizzato 4A, 4



ZA

Albero per guida lineare, Acciaio

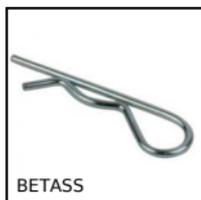

BETASS

Copiglia beta, Beta



PT821

Pignone di trazione, Serie 821 e 805

Prodotti correlati



PRF-GPB

Guide for aluminium profile, Rail for 8mm wide slots



PRF4545

Profilato alluminio standard, 45 x 45 mm