




- **Swivel screen support**
- Can be fixed in the slot or on the end of a PRF4545 aluminium profile, or other profiles with 8mm or 10mm grooves
- For screens conforming to VESA75 and VESA100 mounting standards
- Materials:
  - Support plate - PA plastic reinforced glass fibre
  - Hinge - PA plastic reinforced glass fibre
  - Steel screws and bolts

### Advantages

- Easy to install on an aluminium profile
- Can be mounted horizontally or vertically for optimised visibility
- Precision finish for maximum strength

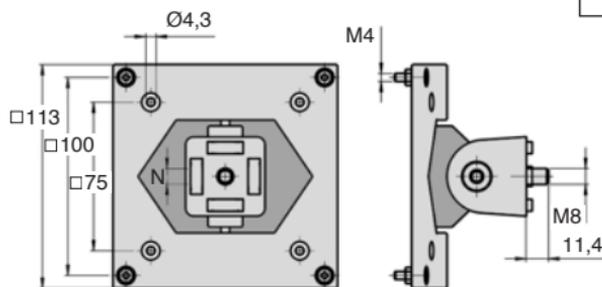

### DISCOUNTS

Qty	1+	3+	5+
Disc. Net		-5%	On request


Part N°	Carrying capacity (kg)	N	Weight (g)	Price each 1 to 2
PRF-SCREEN-1	4,9	8 - 10	200	92,79 €

**Fax** 0 825 88 6000  
Service 0,15 € / min  
+ prix appel

## Altri prodotti...



Supporto a flangia ovale con cuscinetto, Polimero e inox

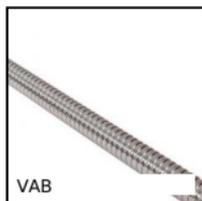

Vite a ricircolo di sfere al metro, Vite a sfere rullata, al metro



Ruota alte temperature, fino a 200kg




Calettatore di bloccaggio, Coppia media/bassa



Guida lineare a sfere - Sfere inox, Binario - da 514 N a 16700 N



Contenitore a becco, 8mm

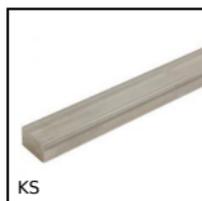

Chiavetta in barre, Inox - in barre



Puleggia dentata di trasmissione tipo HTD, HTD14 Ghisa



Cuscinetto assiale a sfere a semplice effetto, Inox



Screen support, Basic support



Cuscinetto combinato senza anello interno, Needle and cylindrical



Riduttore a ruota e vite senza fine, fino a 40 Nm

## Prodotti correlati



Profilato alluminio standard, 45 x 45 mm



Profilato inox standard, 45 x 45 mm



Screen support, Support with 4 axes of rotation



Screen support, Support with 5 axes of rotation