



Screen support for aluminium profile


Support with 5 axes of rotation PRFSCREEN

- **Screen support on articulated arm**
- Can be fixed in the slot or on the end of a PRF4545 aluminium profile, or on a fixed support
- 360° rotation on the vertical axis
- For screens conforming to VESA75 and VESA100 mounting standards
- Materials :
 - Removable VESA mounting plate - Steel/Plastics
 - Screen holder - Cast aluminium, lacquered
 - Support plate - Cast aluminium, lacquered
 - Adapter - Cast aluminium, lacquered
 - Cable cover - Black plastic
 - Bearings and washers - Black plastic
 - Zinc-plated steel screws



Advantages

- Easy to install on an aluminium profile
- Adjusts in all directions for optimum visibility
- Precision finish for maximum strength

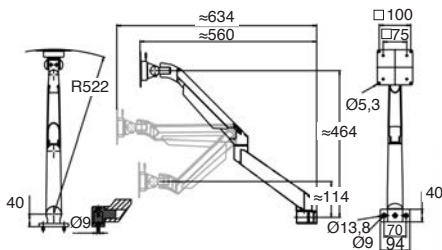


DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Carrying capacity (kg)	Weight (g)	Price each 1 to 2
PRF-SCREEN-5	2 - 10	2930	352,62 €

Fax 0 825 88 6000
 Service 0,15 € / min
 + prix appel

Altri prodotti...

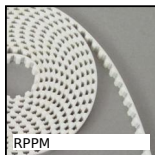


RPPM
Cinghia aperta al metro tipo RPP, RPP5 Poliuretano armatura in acciaio




DOMI120
Accessori di collegamento, Piastra



CHAC404055
Cerniera, Quadrata con rivetto e fori

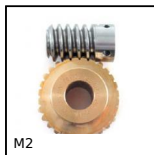

M2
Coppia ruota e vite senza fine, Bronzo

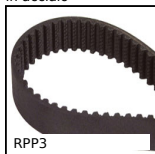

RPP3
Cinghia di trasmissione RPP, RPP3



LSAG
Albero scanalato a sfere, Carello - da 514 N a 15386 N



PLM-C
Magnete cilindrico di fermo, Magnete di fermo cilindrico



SLHHlok
Bloccaggio a leva, A leva orizzontale / base orizzontale



VBFP
Volantino a 6 lobi - boccina passante,



PRF_ROUL
Ruota per profili alluminio, Senza freno



RPB
Vite a ricircolo di sfere, Supporto



FIRSTDC1Q60
Variatore di velocità 10A, 10 A

Prodotti correlati



PRF4545
Profilato alluminio standard, 45 x 45 mm



PRF4545
Profilato inox standard, 45 x 45 mm



PRF-SCREEN-1
Screen support, Basic support



PRF-SCREEN-4
Screen support, Support with 4 axes of rotation