

Magnetic lock for aluminium profile

Easily adjustable lock

PRFSMA

- Lock for sliding doors on systems assembled using PRF454545 aluminium profiles

- Material:

Handle - glass-fibre reinforced PA6

Magnet - Neodymium

Magnet - stainless steel


Back plate - galvanised steel

Advantages

- Easy front-mounting of the handle using M6 CHC screws and the counter plate using M5 FHC screws
- No drilling required

Accessories

- CHC6-16 screws and PRF-ECL-M6 square nut, not provided
- FHC5-12 screws and PRF-ECL-M5 square nut, not provided

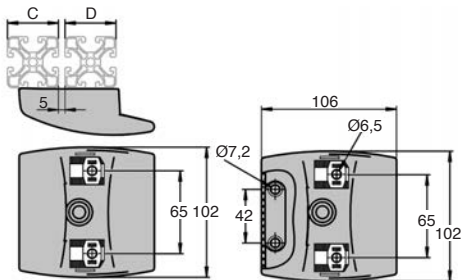

DISCOUNTS

Qty	1+	2+	5+
Disc. Net	-5%	-5%	On request

Part N°	C	D	Holding force (N)	Weight (g)	Price each
PRF-SMA-102	30	38, 1.5" 40, 45, 50, 60	25	168	23,78 €
	40	38, 1.5" 40, 45, 50, 60			
	45	38, 1.5" 40, 45, 50			
	50	38, 1.5" 40, 45, 50			
	60	30, 38, 1.5" 40, 45			

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

241

Altri prodotti...




BIMSS

Pistoncino a molla,
Miniatura inox



CHA1056-UPA

Cerniera su facciata in
poliammide,
Poliammide nera

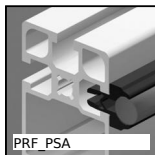

PRF_PSA

Rotella per profilo
alluminio, Supporto
d'albero



CLQ

Cuscinetti a sfere -
Accessorio, Spessori
metallici centesimali a
na...



PLA

Magnete, Magnete
piatto con foro
maschiato



ACLEPP

Angolare, 4 fori



CLG2

Ingranaggio dritto in
plastica stampata ,
Nylon stampato



MSP23

Inserto con piastrina a
incollare
Masterplate®,
Cilindrico Ø23 con...



PFM

Piede senza snodo,
Lamiera modellata



M1

Coppia ruota e vite
senza fine , Bronzo



SCA_SS

Serracavo, Inox



MEP

Impugnatura cilindrica
libera, Fissa

Prodotti correlati



CHC

Vite a testa cava
esagonale CHC,
Acciaio classe 12.19



PRF_ECL

Fissaggio, Dado
quadrato con
linguetta - Acciaio



FHCSS

Vite a testa svasata
piana, Inox A2 - DIN
7991



PRF4545

Profilato alluminio
standard, 45 x 45 mm