


- Base plate for attaching foot or lifting ring
- Fixing kit supplied
- Feet/lifting ring not supplied
- Material: grey powder covered steel

Assembly

- Fits in slot on profile

Accessories

- PR/PRS/PAT/PAM ranges of feet

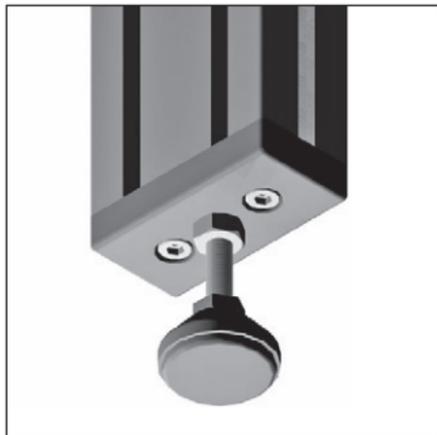

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List	-5%	On request

Part number	For profile	Thickness (mm)	Weight (kg)	Stock*	Price each 1 to 49
PRF4590-BM10	PRF4590	15	0,164	✓	9,71 €
PRF4590-BM12	PRF4590	15	0,162	✓	9,71 €
PRF4590-BM16	PRF4590	15	0,160	✓	9,71 €
PRF4590-BM20	PRF4590	15	0,156	-	9,71 €

*Depending on availability - Dimensions in mm

Altri prodotti...



VTSM

Ball head screws
Hygienic Design®,
Inox



LWL

Guida lineare a sfere -
Sfere inox, Binario -
da 514 N a 16700 N



G1

Ingranaggio dritto
acciaio, Acciaio
20NCD2



PSG15

Ingranaggio dritto di
precisione, Inox 303



NK17

Guida mini Drylin® N,
Larghezza 17 mm



OP3_14_06

Accessorio per
indicatori, Boccola di
riduzione



IBJ

Snodo angolare a
180°, Acciaio



DCG

Ventosa, Gomma
naturale



PSG25

Ingranaggio dritto di
precisione, Acciaio



TCXR

Tenditore per catena
automatico, Con



NT63

Riduttore coassiale a
treni paralleli, da 8 to



PTMC

Telescopio furniture
foot, square plate

Prodotti correlati



PRF4590

Profilato alluminio
standard, 45 x 90 mm



PR40

Piede fissabile con
snodo - poliammide, Ø
40