


- Base plate for attaching foot or lifting ring
- Fixing kit supplied
- Feet/lifting ring not supplied
- Material: grey powder covered steel

Assembly

- Fits in slot on profile

Accessories

- PR/PRS/PAT/PAM ranges of feet

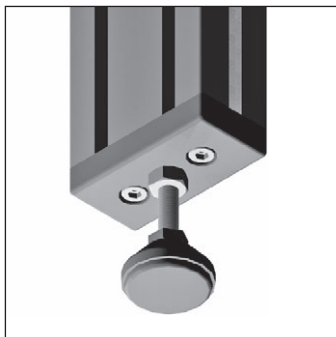

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List	-5%	On request

Part number	For profile	Thickness (mm)	Weight (kg)	Stock*	Price each 1 to 49
PRF4590-BM10	PRF4590	15	0,164	✓	9,71 €
PRF4590-BM12	PRF4590	15	0,162	✓	9,71 €
PRF4590-BM16	PRF4590	15	0,160	✓	9,71 €
PRF4590-BM20	PRF4590	15	0,156	-	9,71 €

*Depending on availability - Dimensions in mm

Altri prodotti...



SCE
Serracavo, Acciaio



DTR
Pignone tendicatena,
Ruota dentata in
acciaio



MEF
Cuscinetto cilindrico ,
Lega di ferro FP20
autolubrificante
METAFRAM




B_ECO
Ingranaggio conico -
Acciaio C43 - ECO, 1:1



G1
Ingranaggio dritto
acciaio, Acciaio
20NCD2



ACLBT5
Sistema di chiusura,
Blocca porta a sfera

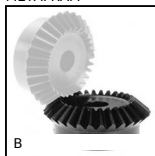

B
Ingranaggio conico -
Acciaio 60C40, 1:1



COA-COG
Staffa di montaggio
per molla a gas,
Staffa di montaggio
piana per f...



G-ECO15
Ingranaggio dritto
acciaio - serie ECO,
20NCD2



EKGS
Giunto senza gioco
Gerwah®, da 0.5 a
20 mm



TFR
Tenditore rigido, Fisso



PRS80
Piede snodato tutto
inox Ø80, Ø 80

Prodotti correlati



PRF4590
Profilato alluminio
standard, 45 x 90 mm



PR40
Piede fissabile con
snodo - poliammide, Ø
40