


- Base plate for attaching foot or lifting ring
- Fixing kit supplied
- Feet/lifting ring not supplied
- Material: grey powder covered steel

Assembly

- Fits in slot on profile

Accessories

- PR/PRS/PAT/PAM ranges of feet

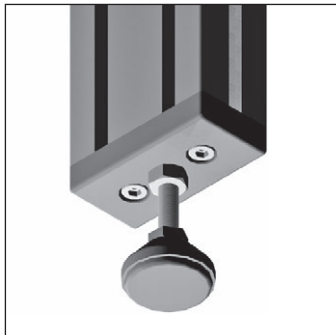

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List	-5%	On request

Part number	For profile	Thickness (mm)	Weight (kg)	Stock*	Price each 1 to 49
PRF4590-BM10	PRF4590	15	0,164	✓	9,71 €
PRF4590-BM12	PRF4590	15	0,162	✓	9,71 €
PRF4590-BM16	PRF4590	15	0,160	✓	9,71 €
PRF4590-BM20	PRF4590	15	0,156	-	9,71 €

*Depending on availability - Dimensions in mm


Altri prodotti...



Q7
Cuscinetto obliquo a sfere, Acciaio




PM2
Coppia ruota e vite senza fine, Acciaio non temprato

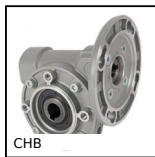

CHB
Riduttore a ruota e vite senza fine, fino a 22 Nm



AFSE
Perno di fissaggio, con chiusura a scatto

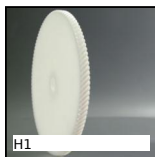

H1
Ingranaggio elicoidale ad assi incrociati a 90°, Plastica lavorata



PCS8ECO
Pignone a catena - acciaio, 8mm (DIN 05B-1)



PSEC
Maniglia a ponte di sicurezza, Termoplastica




VCMB
Vite di giunzione metallo/legno, Acciaio



MHX
Manicotto esagonale maschiato, Esagonale - inox



KB_UU
Manicotto a sfere di precisione, Di precisione - acciaio

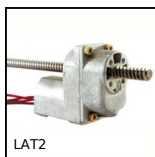

LAT2
Attuatore lineare a motore 2A, 2 ampere



RBNpl
Ruota girevole con piastra, Acciaio - caucciù

Prodotti correlati



PRF4590
Profilato alluminio standard, 45 x 90 mm



PR40
Piede fissabile con snodo - poliammide, Ø 40