



 

## For mounting additional panels

# MiniTecPRFBV

- For the addition of panels with a wall thickness of 2-6 mm
- Can be used with all solid panels (not mesh grills)
- Allow 2mm for assembly (reduce panel size to leave 1mm on each side)
- Material: grey polyamide

### Assembly

- Mount the block in the profile slot at the required position
- Offer the pre-drilled panels into the aperture
- Secure the panels using suitable M6 screws
- Note: Hole distance, 7.5-16mm from edge

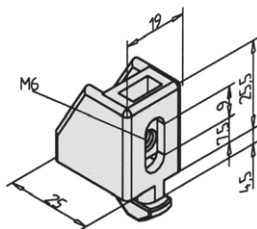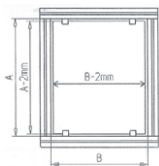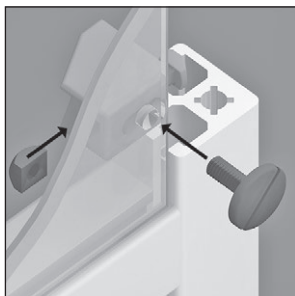

### DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	For profile	Weight (kg)	Stock*	Price each 1 to 49
PRF-BV	all types from PRF32	0,01	✓	3,09 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...




PW\_PWG3

Vite senza fine di precisione, Acciaio



RIMple

Ruota di livellamento, Con piastra

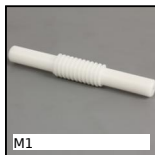


M1

Coppia ruota e vite senza fine, Plastica lavorata (delrin)



WS16

Binario Drylin® W, Binario

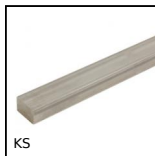

KS

Chiavetta in barre, Inox - in barre



PCatherm

Pull handle, Thermoplastic



CFF

Testa a snodo femmina DIN ISO12240-4, Acciaio / bronzo



DOMI120

Accessori di collegamento, Piatto girevole



GE\_C

Snodo sferico, Cromo duro/PTFE



GLT3-46

Guide telescopiche acciaio, Estensione totale



CM\_CO

Attrezzi Hygienic Usit® and Hygienic Design®, Protective



TBbutee

Cuscinetto assiale a sfere a semplice effetto, Sfere acciaio

## Prodotti correlati



PRF4545

Profilato alluminio standard, 45 x 45 mm