





## For mounting additional panels

# MiniTecPRFBV

- For the addition of panels with a wall thickness of 2-6 mm
- Can be used with all solid panels (not mesh grills)
- Allow 2mm for assembly (reduce panel size to leave 1mm on each side)
- Material: grey polyamide

### Assembly

- Mount the block in the profile slot at the required position
- Offer the pre-drilled panels into the aperture
- Secure the panels using suitable M6 screws
- Note: Hole distance, 7.5-16mm from edge

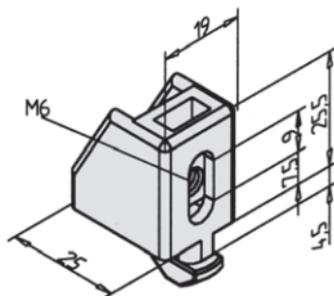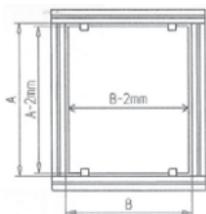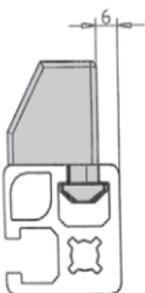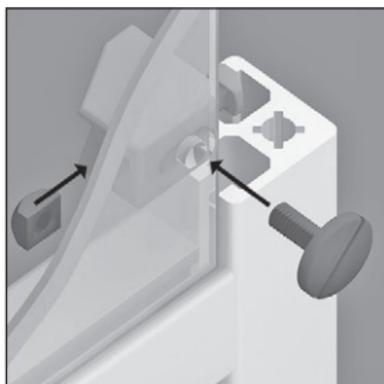

### DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	For profile	Weight (kg)	Stock*	Price each 1 to 49
PRF-BV	all types from PRF32	0,01	✓	3,09 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...



DOMI30

Accessori di collegamento, Kit di fissaggio



PF60

Riduttore a ruota e vite senza fine, fino a 118 Nm



PAL

Dado di sicurezza, Per bloccaggio assiale



BLHB60

Rinvio angolare ad albero cavo, fino a 70 Nm



PRES

Accessori per pressa PRES-3HR e PRES-4HR, Coppia di dadi per scanala...



VT

Limitatore di coppia ad attrito Vari-Tork®, 0.53 a 1.32 Nm



IN1

Ingranaggio interno, Acciaio 20NCD2



UGH32

Unità di guida tipo H, Per martinetti Ø 32



AC

Piastrina di riscontro, 12,13,18 e 20mm



HAR9

Rondella girevole, DIN 6371



RBNpl

Ruota girevole a doppio bloccaggio,



CHAFR-MINI

Cerniera, A frizione

## Prodotti correlati



PRF4545

Profilato alluminio standard, 45 x 45 mm