




For mounting additional panels

MiniTecPRFBV

- For the addition of panels with a wall thickness of 2-6 mm
- Can be used with all solid panels (not mesh grills)
- Allow 2mm for assembly (reduce panel size to leave 1mm on each side)
- Material: grey polyamide

Assembly

- Mount the block in the profile slot at the required position
- Offer the pre-drilled panels into the aperture
- Secure the panels using suitable M6 screws
- Note: Hole distance, 7.5-16mm from edge

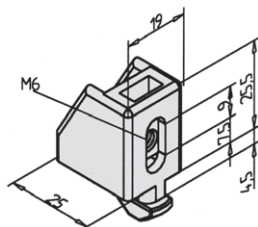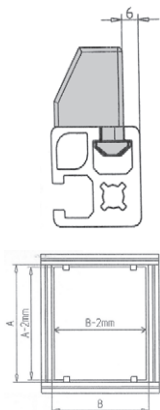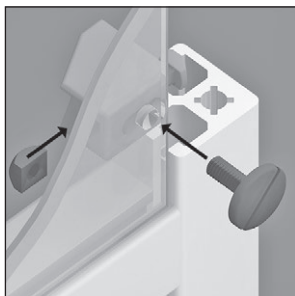

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	For profile	Weight (kg)	Stock*	Price each 1 to 49
PRF-BV	all types from PRF32	0,01	✓	3,09 €

*Depending on availability - Dimensions in mm

Altri prodotti...



ESCON

Accessori per variatore di velocità 5A, Kit 4 cavi motore DC



PWC

Inseri filettati, Kit Powercoil - con o senza attrezzo di posa



BCAss

Boccola scanalata Inox, Inox



BPHT

Sfera portante fissaggio con perno filettato, Forte



DGSA

Testa a snodo maschio, Acciaio / acciaio - Serie economica



DCG

Ventosa, nitrile



SHN

Dado esagonale - DIN934, Acciaio (Class 6|8)



EMAS

Antistatic knurled nut, Antistatic



RAGFLOW

Rotaia a rulli Floway2®, Rotaia a rulli



RT61ss

Calettatore di bloccaggio, Coppia media/bassa



DOG258

Motoriduttore DC 12V e 24V DC, da 12 a 15 Nm



BPM_LOK

Pressore a molla con intaglio e puntale a sfera, LONG-LOK - Acciaio

Prodotti correlati



PRF4545

Profilato alluminio standard, 45 x 45 mm