



- Material: electroplated steel
- 4 electroplated M8 x14mm grub screws (use SW4 hexagonal key or PRF-TOOL-H4 tool)

Uses


- For but joining profiles.
- For creating longer profiles

Assembly

- Simply twist into slot in profile
- No preparation required
- For long profiles or to support heavier loads, use more joining bars.

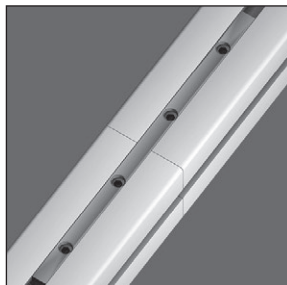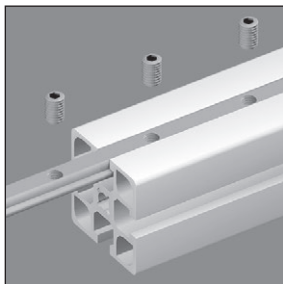

Typical application

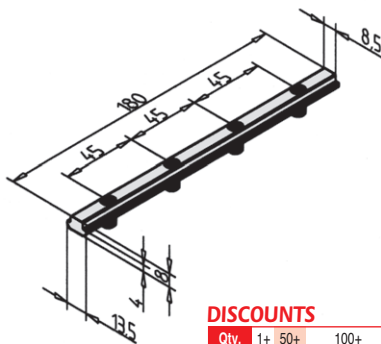

DISCOUNTS

| | | | |
|-------|----------|------------|------|
| Qty. | 1+ | 50+ | 100+ |
| Disc. | List -5% | On request | |

| Part number | Type | Weight (kg) | Stock* | Price each 1 to 49 |
|-------------|-------------|-------------|--------|--------------------|
| PRF-ER-180 | Joining bar | 0,12 | ✓ | 10,79 € |


*Depending on availability - Dimensions in mm

Altri prodotti...



PARF80

Piede senza snodo,
Piede snodato
oscillante fissabile
Ø80

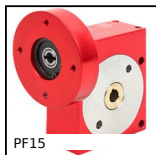

PF15

Riduttore a ruota e
vite senza fine, fino a
3,75 Nm



GAL48_OMNI

Ruota per
trasportatore,
Omnidirezionale



PSPD40

Manopola a pressione,
PVC nero



RTK

Giunto Bowex ®, a
dentatura bombata,
Nylon e acciaio



DB

Ingranaggio conico -
Acciaio 60C40, 2:1



ASM

Cuscinetto cilindrico ,
Polimero alimentare



CTss

Giunto cardanico
telescopico inox,
Sollecitazioni leggere



HTD8M_50

Puleggia dentata di
trasmissione tipo
HTD, HTD8 Acciaio



SH1

Ingranaggio elicoidale
ad assi paralleli,
Plastica lavorata
(delrin)



KB_UU

Manicotto a sfere di
precisione, Di
precisione - acciaio



TBEBASE

Base plate for
economic mini-table,
Allows X-Y cross
tables

Prodotti correlati



PRF4545

Profilato alluminio
standard, 45 x 45 mm