

Fastener for aluminium profile

Stock

PRF MiniTec

Standard fastener

FIXSTD

Profile assembly





- Suitable for loads up to 18000N
- Can be used to securely join all profile types
- Forms very efficient anti-twist joint
- Materials:
 - M8x50mm CHC screw: electroplated steel
 - Locking plate: electroplated steel

Uses

- For heavy or vibrating loads

Assembly

- Drill a stepped hole ($\varnothing 9$, $\varnothing 15$) at the required position
- Slide the screw locking plate in the slot
- Pass the end of the screw through the first profile (1), the locking plate and then into the central hole of the second profile (2) which was previously tapped (M8 x 25mm) and tighten.

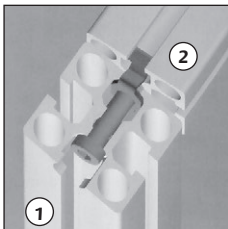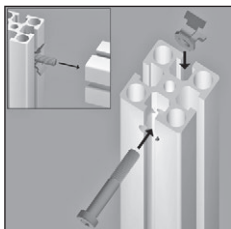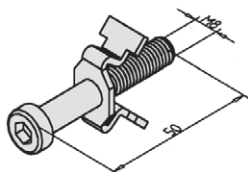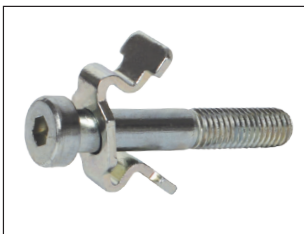

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List	-5%	On request

Part number	Load (N)	For profile	Tightening torque (Nm)	Weight (kg)	Stock*	Price each 1 to 49
PRF-FIX-STD	18000	All types of PRF profile	20	0,03	✓	1,96 €

*Depending on availability - Dimensions in mm

Altri prodotti...



ACLEFS
Elementi di ancoraggio, Regolabile



HFL
Ruota libera, Combinata ad aghi



VPSS
Volantino a 6 lobi, Duroplast - Inox



LWL
Guida lineare a sfere - Sfere inox, Carello - da 514 N a 16700 N



BTCW
Tappo inox per tubo quadrato, A saldare



PSG15S
Ingranaggio dritto di precisione, Inox 316



OPFL_OPPM
Accessorio per indicatori, Flangia blocco albero



CHT
Motore AC asincrono trifase, 0.55 a 1.1kW



SER69K
Chiusura 1/4 di giro per agroalimentare, Inox



PGR
Impugnatura cilindrica libera retraibile, Retraibile



BPTR_M
Tappo per tubo, Con inserto maschiato



GMK17_BROSSE
Spazzola, Per imbottigliamento e imballaggio

Prodotti correlati




PRF1932
Profilato alluminio standard, 19 x 32 mm



PRF4545
Profilato inox standard, 45 x 45 mm



PRF_FIX_UNI
Fissaggio, universale

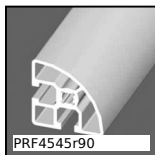

PRF4545r90
Profilato alluminio standard, 45 x 45 mm - R90°