

Fastener for aluminium profile

Stock

PRF MiniTec

Standard fastener

FIXSTD

Profile assembly




- Suitable for loads up to 18000N
- Can be used to securely join all profile types
- Forms very efficient anti-twist joint
- Materials:
 - M8x50mm CHC screw: electroplated steel
 - Locking plate: electroplated steel

Uses

- For heavy or vibrating loads

Assembly

- Drill a stepped hole ($\varnothing 9$, $\varnothing 15$) at the required position
- Slide the screw locking plate in the slot
- Pass the end of the screw through the first profile (1), the locking plate and then into the central hole of the second profile (2) which was previously tapped (M8 x 25mm) and tighten.

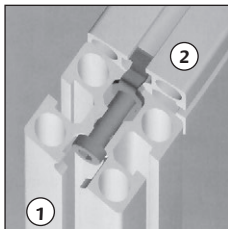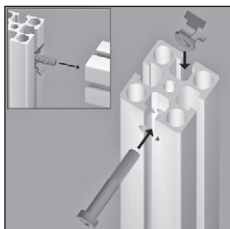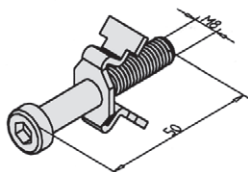

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List	-5%	On request

Part number	Load (N)	For profile	Tightening torque (Nm)	Weight (kg)	Stock*	Price each 1 to 49
PRF-FIX-STD	18000	All types of PRF profile	20	0,03	✓	1,96 €

*Depending on availability - Dimensions in mm

Altri prodotti...



T10_21_AL

Puleggia dentata di posizionamento tipo T, Serie economica - T10 all...



SLB

Pistoncino a molla, inox



CHT

Motore AC asincrono trifase, 0.55 a 1.1kW



HW_HT

Guida su semi-binari, Ruota



PPF

Pistoncino a molla, con flangia



AC

Piastrina di riscontro, 12,13,18 e 20mm



BPL

Sfera portante con flangia, Leggero



NIN

Dado autofrenante , inox A2



WW10

Guida Drylin® W, Carrello



VPSS

Volantino a 6 lobi, Duroplast - Inox



CHML63

Riduttore a ruota e vite senza fine, fino a 138 Nm - Con limitatore ...



SLH

Attrezzo di bloccaggio a leva orizzontale, A leva orizzontale - acci...

Prodotti correlati



PRF1932

Profilato alluminio standard, 19 x 32 mm




PRF4545

Profilato inox standard, 45 x 45 mm



PRF_FIX_UNI

Fissaggio, universale

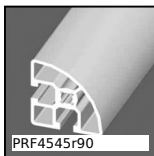

PRF4545r90

Profilato alluminio standard, 45 x 45 mm - R90°